

- For joining or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

### Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

### Info

- Also available in steel



**Economy range**

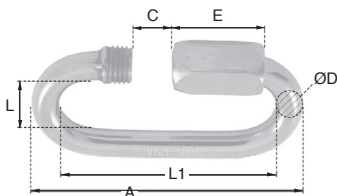

### DISCOUNTS

| Qty   | 1+   | 20+ | 40+  | 60+  | 80+  | 100+       |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number    | ØD   | A     | L1   | L    | C    | E    | Nominal load (kg) | Weight (g) | Stock* | Price each |
|----------------|------|-------|------|------|------|------|-------------------|------------|--------|------------|
|                |      |       |      |      |      |      |                   |            |        | 1 to 19    |
| MRA1-03/SS/ECO | 3,5  | 37,2  | 30,4 | 9,7  | 5,5  | 12,6 | 220               | 8          | ✓      | 3,58 €     |
| MRA1-04/SS/ECO | 4,0  | 41,0  | 33,0 | 11,7 | 6,3  | 12,7 | 280               | 12         | ✓      | 3,89 €     |
| MRA1-05/SS/ECO | 5,0  | 51,2  | 41,0 | 13,0 | 7,0  | 17,0 | 450               | 22         | ✓      | 4,40 €     |
| MRA1-06/SS/ECO | 6,0  | 59,0  | 47,0 | 14,7 | 8,8  | 20,0 | 650               | 36         | ✓      | 4,98 €     |
| MRA1-07/SS/ECO | 7,0  | 67,7  | 54,0 | 18,3 | 9,7  | 23,7 | 900               | 54         | -      | 8,53 €     |
| MRA1-08/SS/ECO | 8,0  | 74,6  | 59,0 | 18,3 | 9,9  | 25,0 | 1100              | 76         | ✓      | 9,99 €     |
| MRA1-10/SS/ECO | 10,0 | 89,0  | 70,0 | 22,2 | 12,8 | 30,0 | 1800              | 138        | -      | 17,28 €    |
| MRA1-12/SS/ECO | 12,0 | 105,0 | 82,0 | 24,8 | 14,2 | 34,0 | 3500              | 224        | -      | 27,66 €    |

\*Depending on availability - Dimensions in mm

## Our other products



M1

Worm and wheel set,  
Non hardened steel




ACLALF

Adjustable foot for  
aluminium profile,  
Ideal for workstations



HCA

Magnetic screw with  
socket, Steel

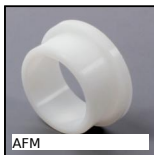

AFM

Flanged polymer  
bush, Food grade  
polymer



SRG

Adjustable latch  
clamp with catch-  
plate, Stroke from  
77,3mm to 83mm



AXTR

Axle for tensioner  
pulley, Shaft



BAC105

Storage bin, 8mm



CHAC4040SS

Square hinge with  
riveted pin, drilled,  
Square with riveted  
pin, dri...



 
INS\_BR

Self tapping brass  
insert, Brass



WINGbr

Wing screw, hand  
tightened, Brass DIN  
316



MLY

Bow shackle with eye  
bolt, Steel



PLM-C

Cylindrical holding  
magnets, Cylindrical  
holding magnet

## Complementary products



CHN\_CHNSS

Straight long link  
stainless steel chain,  
Stainless steel



MRA\_SS

Stainless steel Quick  
link, Stainless steel



PPRss

Pad eye on mounting  
plate, Stainless steel