


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

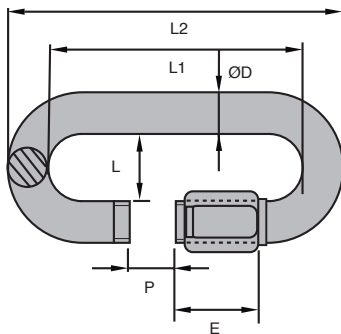

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



Clevis components, short version, Stainless steel - short range



Retaining clamp, single sided, Single sided



Indexing plunger mini, miniature



Cam follower without axial guide, With interior ring



Crossed helical gear, crossed axis at 90°, Steel 20NCD2



Female rod ends DIN ISO12240-4, Steel / bronze



Steel splined shaft, Steel



Stainless steel gas spring, Stainless steel



Worm - precision range, Steel



Fixed rubber levelling foot, Levelling support



Right angled gearbox, from 19 to 70 Nm



Hexagonal nut DIN934, Brass

Complementary products



Straight long link stainless steel chain, Stainless steel



Low cost stainless steel quick link, Stainless steel



Pad eye on mounting plate squarred, Stainless steel