

Low cost quick link



MRAECO

Link diameter 3.5-16mm

- For joining or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter




Economy range

Application

- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in stainless steel

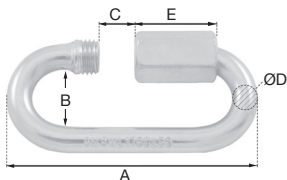

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	B	C	E	Nominal load (kg)	Weight (g)	Stock*	Price each
									1 to 19
MRA1-03/ECO	3,5	36,0	10,0	5,0	12,0	100	8	✓	0,49 €
MRA1-04/ECO	4,0	39,5	11,5	6,0	14,0	180	12	✓	0,60 €
MRA1-05/ECO	5,0	49,5	13,0	7,0	17,0	280	22	-	0,66 €
MRA1-06/ECO	6,0	57,0	14,5	8,0	20,0	400	36	✓	0,82 €
MRA1-07/ECO	7,0	66,0	16,0	9,0	22,5	550	52	-	1,10 €
MRA1-08/ECO	8,0	74,0	17,5	10,0	24,0	700	76	✓	1,28 €
MRA1-09/ECO	9,0	80,0	19,0	11,0	27,0	900	110	-	1,78 €
MRA1-10/ECO	10,0	89,0	20,5	12,0	30,0	1100	146	✓	2,37 €
MRA1-12/ECO	12,0	104,5	23,5	14,0	34,0	1500	234	-	3,64 €
MRA1-14/ECO	14,0	121,0	26,5	17,0	39,0	2200	358	-	7,25 €
MRA1-16/ECO	16,0	140,0	29,5	19,0	43,0	2900	520	-	11,78 €

*Depending on availability - Dimensions in mm

Our other products



PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



PRF_BASE

Base plate for aluminium profile, Base plate



AT10-BAR

AT type tooth bar stock, AT10



P40

Worm and wheel gear reducer, up to 18 Nm



RBntc

Swivel castor with central hole, Steel - rubber



NKXR

Combined bearing without inner ring, Needle and cylindrical rollers



G01

Single universal joint, Normal duty



PRF4590

Standard aluminium profile, 45 x 90 mm



PRF_CHA

Hinge for aluminium profile, Surface mounting hinge



 
PGNT

Thermoplastic T handle, With threaded spindle



LPCM

Lever with cylindrical handle, Black Duroplast, steel lever



EZYSS

Stainless steel cylindrical stop, stainless steel

Complementary products



MRA

Quick link, Steel



MRA_SS

Stainless steel Quick link, Stainless steel



MRASSeco

Low cost stainless steel quick link, Stainless steel



CHN_CHNSS

Straight long link chain, Galvanised steel