

- For joining or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter




Application

- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in stainless steel

Economy range

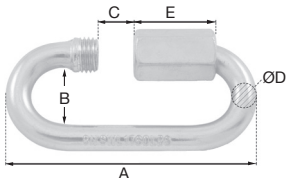

DISCOUNTS

| Qty | 1+ | 20+ | 40+ | 60+ | 80+ | 100+ |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØD | A | B | C | E | Nominal load (kg) | Weight (g) | Stock* | Price each 1 to 19 |
|-------------|------|-------|------|------|------|-------------------|------------|--------|--------------------|
| MRA1-03/ECO | 3,5 | 36,0 | 10,0 | 5,0 | 12,0 | 100 | 8 | ✓ | 0,49 € |
| MRA1-04/ECO | 4,0 | 39,5 | 11,5 | 6,0 | 14,0 | 180 | 12 | ✓ | 0,60 € |
| MRA1-05/ECO | 5,0 | 49,5 | 13,0 | 7,0 | 17,0 | 280 | 22 | - | 0,66 € |
| MRA1-06/ECO | 6,0 | 57,0 | 14,5 | 8,0 | 20,0 | 400 | 36 | ✓ | 0,82 € |
| MRA1-07/ECO | 7,0 | 66,0 | 16,0 | 9,0 | 22,5 | 550 | 52 | - | 1,10 € |
| MRA1-08/ECO | 8,0 | 74,0 | 17,5 | 10,0 | 24,0 | 700 | 76 | ✓ | 1,28 € |
| MRA1-09/ECO | 9,0 | 80,0 | 19,0 | 11,0 | 27,0 | 900 | 110 | - | 1,78 € |
| MRA1-10/ECO | 10,0 | 89,0 | 20,5 | 12,0 | 30,0 | 1100 | 146 | ✓ | 2,37 € |
| MRA1-12/ECO | 12,0 | 104,5 | 23,5 | 14,0 | 34,0 | 1500 | 234 | - | 3,64 € |
| MRA1-14/ECO | 14,0 | 121,0 | 26,5 | 17,0 | 39,0 | 2200 | 358 | - | 7,25 € |
| MRA1-16/ECO | 16,0 | 140,0 | 29,5 | 19,0 | 43,0 | 2900 | 520 | - | 11,78 € |

*Depending on availability - Dimensions in mm

Our other products



EFTC
Fixing support,
Stainless steel



VDSCB
Sliding lock
adjustment system,
Blocking wedge for
sliding lock for ...



PRF_ART
Articulated bracket for
use with aluminium
profile, With clamping
ha...




HTD5M_25
HTD Heavy duty
timing pulley, HTD5
Aluminium



GARQT
Quarter turn lock pin
for clamping, Quarter
turn



GCB880
Curved track for slat
top chain, Ranges 880
and 881

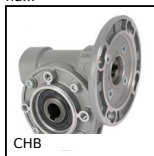

CHB
Worm and wheel gear
reducer, up to 22 Nm



PCS6ECO
Chain sprocket - steel,
6mm (DIN 04-1)



MSP23
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with



PAMF120
Articulated fixable
foot, pressed bolt-
down base Ø 120, Ø



M0
Worm and wheel set,
Non hardened steel



FF50
Offset spur gear
reducer, from 111 to
425 Nm

Complementary products



MRA
Quick link, Steel



MRA_SS
Stainless steel Quick
link, Stainless steel



MRASSeco
Low cost stainless
steel quick link,
Stainless steel



FCHN_CHNSS
Straight long link
chain, Galvanised
steel