

Low cost quick link



MRAECO

Link diameter 3.5-16mm

- For joining or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter




Economy range

Application

- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in stainless steel

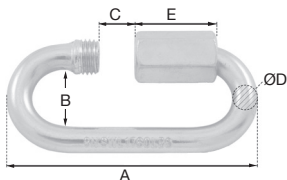

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	B	C	E	Nominal load (kg)	Weight (g)	Stock*	Price each 1 to 19
MRA1-03/ECO	3,5	36,0	10,0	5,0	12,0	100	8	✓	0,49 €
MRA1-04/ECO	4,0	39,5	11,5	6,0	14,0	180	12	✓	0,60 €
MRA1-05/ECO	5,0	49,5	13,0	7,0	17,0	280	22	-	0,66 €
MRA1-06/ECO	6,0	57,0	14,5	8,0	20,0	400	36	✓	0,82 €
MRA1-07/ECO	7,0	66,0	16,0	9,0	22,5	550	52	-	1,10 €
MRA1-08/ECO	8,0	74,0	17,5	10,0	24,0	700	76	✓	1,28 €
MRA1-09/ECO	9,0	80,0	19,0	11,0	27,0	900	110	-	1,78 €
MRA1-10/ECO	10,0	89,0	20,5	12,0	30,0	1100	146	✓	2,37 €
MRA1-12/ECO	12,0	104,5	23,5	14,0	34,0	1500	234	-	3,64 €
MRA1-14/ECO	14,0	121,0	26,5	17,0	39,0	2200	358	-	7,25 €
MRA1-16/ECO	16,0	140,0	29,5	19,0	43,0	2900	520	-	11,78 €

*Depending on availability - Dimensions in mm

Our other products



CHA225

Screwed hinge with threaded insert, 225 degrees



BLHT30

Right angled gearbox, from 1.65 to 4.40 Nm



TPEpbd

Castor for aluminium profile, Swivel with brake



LRR

Catch-plate for latch, Catch-plate



PSG1

Spur gear - precision range, Case hardened steel 20NCD2




NCT

Square tube connector, Fixed angle



SVR30

 Screwjack with travelling nut, with moving nut



NCT

Square tube connector, Fixed angle



MAX22

Motor-gearbox 12V and 24V DC, from



GMK17_R

Round guide, Round guide for conical



SCH

Horizontal hook toggle clamp,



PGT

Sliding profile, Sliding panel support

Complementary products



MRA

Quick link, Steel



FCHN_CHNSS

Straight long link chain, Galvanised steel