

# Sta Stock Stainless steel metric section rack

 

Stainless steel

Module  
**1.0-3.0**

- Racks can easily be joined end to end
- Pressure angle 20°
- Material:  
drawn stainless steel 304

## Option

- Other lengths available for quantities of 10 or more, please contact us

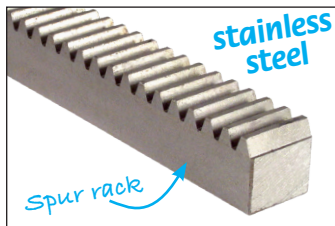

## DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	W (mm)	H (mm)	Primitive line P (mm)	Length L (mm)	Stock*	Price each 1 to 2
MRS1-1000	1,0	10	10	9,00	999	✓	78,18 €
MRS1.5-1000	1,5	15	15	13,50	999	✓	224,02 €
MRS2-1000	2,0	20	20	18,00	999	✓	244,89 €
MRS2.5-1000	2,5	25	25	22,50	999	-	On request
MRS3-1000	3,0	30	30	27,00	999	✓	429,90 €

\*Depending on availability - Dimensions in mm

## Our other products



CHT

Asynchronous AC motor , 0.09kW



RBS

Dynamic washer  
DIN2093, Steel




H02

Single needle roller  
universal joint, Heavy  
duty



KB\_OP

Open precision linear  
bearing, Precision -  
steel

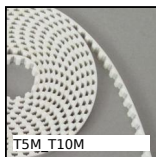

T5M T10M

T type timing belt per  
metre, T5 Steel cored  
polyurethane



DFG

Flat suction cup,  
silicon



CHTRP

Single and dual  
output gearboxes, Up  
to 87,3Nm



FIRSTDC1Q60

Speed controller 10A,  
10 A



ATZYSS

Stainless steel diablo  
shaped elasto mount,  
Stainless steel



DB

Steel bevel gear, 2:1



SVT30


Screwjack with  
travelling screw, with  
translating screw



NK40

Drylin®N miniature  
guiding system, Width  
40 mm

## Complementary products

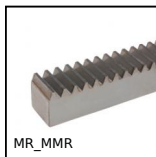

MR\_MMR

Metric section rack,  
Steel



SSG1

Stainless steel spur  
gear, Stainless steel  
304L



SSG1\_304L

Stainless steel spur  
gear, Stainless steel  
304L