 



- Racks can easily be joined end to end
- Pressure angle 20°
- Material:
drawn stainless steel 304

Option

- Other lengths available for quantities of 10 or more, please contact us

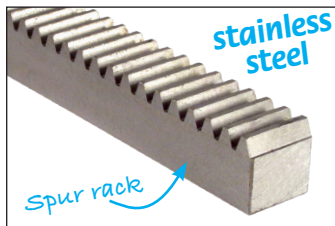

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	W (mm)	H (mm)	Primitive line P (mm)	Length L (mm)	Stock*	Price each 1 to 2
MRS1-1000	1,0	10	10	9,00	999	✓	78,18 €
MRS1.5-1000	1,5	15	15	13,50	999	✓	224,02 €
MRS2-1000	2,0	20	20	18,00	999	✓	244,89 €
MRS2.5-1000	2,5	25	25	22,50	999	-	On request
MRS3-1000	3,0	30	30	27,00	999	✓	429,90 €

*Depending on availability - Dimensions in mm

Our other products



TBD

Manual leadscrew table with opposing threads, 2kg



 
VHEH

Hexagonal headed screw with collar Hygienic Usit®, Stainless steel



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



Q3

Double row angular contact ball bearing, Angular contact - Steel



PTMR

Telescopic furniture foot, threaded stud



GLT2-17

Telescopic drawer runners for groove mounting, Partial extension



MBEX

Hexagonal ended handle, Hexagonal ended handle



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



M2

Worm and wheel set, Bronze



RT61ss

Self-centering locking Assembly,



BLHT20


Right angled gearbox, from 0.66 to 1.77 Nm



NPTF30

Fixed tube carrier, Fixed Ø14 to Ø20

 Complementary products



MR_MMR

Metric section rack, Steel



SSG1

Stainless steel spur gear, Stainless steel 304L



SSG1_304L

Stainless steel spur gear, Stainless steel 304L