

# Sta Stock Stainless steel metric section rack

 

Stainless steel

Module  
**1.0-3.0**

- Racks can easily be joined end to end
- Pressure angle 20°
- Material:  
drawn stainless steel 304

## Option

- Other lengths available for quantities of 10 or more, please contact us

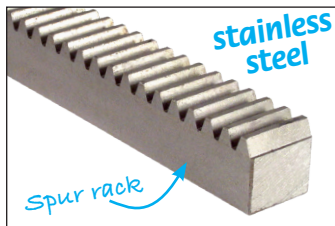

## DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	W (mm)	H (mm)	Primitive line P (mm)	Length L (mm)	Stock*	Price each 1 to 2
MRS1-1000	1,0	10	10	9,00	999	✓	78,18 €
MRS1.5-1000	1,5	15	15	13,50	999	✓	224,02 €
MRS2-1000	2,0	20	20	18,00	999	✓	244,89 €
MRS2.5-1000	2,5	25	25	22,50	999	-	On request
MRS3-1000	3,0	30	30	27,00	999	✓	429,90 €

\*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB  
04/2020

**HPC**

## Our other products



DB  
Steel bevel gear, 2:1



TCL-CR  
T-Clip - Aluminium  
profile attachment,  
Hook



LRR  
Catch-plate for latch,  
Catch-plate



VLBS  
Folding lifting ring for  
welding, Folding - for  
welding



CHM30-MOT  
Asynchronous AC  
motorgearboxes 0.09  
to 0.22kW, 0.09 to  
0.22kW



V3RA\_PT  
3-spoked handwheel  
with handle,  
Polyamide



METC  
Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



 
PRES7HR  
Manual workbench  
press, Force up to  
700kg



SHTP  
Drylin® Linear table,  
Economy range



TRMSS  
Spur round rack,  
Stainless steel -  
module 1-5




PX\_PO  
Carrying handle,  
standard



E60B  
Right angle helical  
reducers, from 4.50 to  
24 Nm

## Complementary products

 

MR\_MMR  
Metric section rack,  
Steel



SSG1  
Stainless steel spur  
gear, Stainless steel  
304L



SSG1\_304L  
Stainless steel spur  
gear, Stainless steel  
304L