

Cylindrical Master-Plate® glueable insert

MSP19
MSP20

316L stainless steel

- Glueable stainless steel plate with tapped insert or threaded stud
- Material:
316L stainless steel

Applications

 
- Industrial, transport, building, furnishings

Info.


- Glue not supplied
- Not supplied individually, contact us for details




316L stainless steel




MSP19

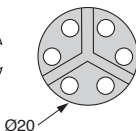


MSP20

 

Tapped

 

Nut

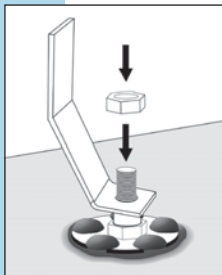

Typical application



DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request

Part number	ØA	ØD	L	Form	Prix Uni. 1 à 49
MSP19TB-5-20/SS	19	M5	20	Blind tapped	7,81 €
MSP19E-4-3/SS	19	M4	3,2	Nut	1,90 €
MSP19E-5-4/SS	19	M5	4	Nut	1,93 €
MSP20E-5-4/SS	20	M5	4	Nut	1,95 €

Our other products



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



SDG_SS

Universal adjustable guide support bracket, Stainless steel



RBNtc

Swivel castor with central hole, Steel - rubber - with double brake




GE_ES_2RS

Spherical bushing, Steel / steel with seals



BLHT60

 Right angled gearbox, from 26 to 70 Nm



PTR

Idler chain sprocket, For standard applications



PLS

Cylindrical spacer, Stainless steel 303



ADL_F

Female eye bolt conforms to DIN582, Steel



CABtool

Fitting cable tools, Cutting tools



ZBconique

Machined plastic bevel gear , 1:1



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm

Complementary products



MSP3815

Masterplate® glueable insert rectangular, rectangular with

tapped i...



MSP38

Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
threaded s...



MSP23

Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
threaded s...



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with nut