

Cylindrical Master-Plate® glueable insert

MSP19
MSP20

316L stainless steel

- Glueable stainless steel plate with tapped insert or threaded stud
- Material:
316L stainless steel

Applications

 
- Industrial, transport, building, furnishings

Info.


- Glue not supplied
- Not supplied individually, contact us for details




316L stainless steel




MSP19

 


MSP20

 

Tapped

 

Nut

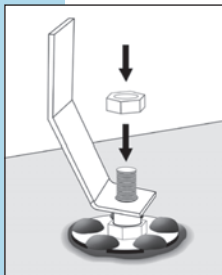

Typical application



DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request

Part number	ØA	ØD	L	Form	Prix Uni. 1 à 49
MSP19TB-5-20/SS	19	M5	20	Blind tapped	7,81 €
MSP19E-4-3/SS	19	M4	3,2	Nut	1,90 €
MSP19E-5-4/SS	19	M5	4	Nut	1,93 €
MSP20E-5-4/SS	20	M5	4	Nut	1,95 €

Our other products



Q6

Deep groove ball bearing, Steel



G4-ECO

Eco range Spur gear, Steel C45



RTE

Rotex®, jaw coupling, cast iron



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2




CHTRP

Single and dual output gearboxes, Up to 75,7 Nm



YG2

 HEAVY DUTY spur gear, Steel 35NCD6



VAB

Ball screw, supplied by the metre, Rolled ball screw, per metre



VCMB

Dual-thread screw wood/metal, Steel



ACLEPP

Right angled bracket for aluminium profile, 4 holes



HK

Manual locking clamp, Manual locking clamp LRX



PSG1

Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products



MSP3815

Masterplate® glueable insert rectangular, rectangular with

tapped i...



MSP38

Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
threaded s...



MSP23

Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
threaded s...



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with nut