

# Cylindrical Master-Plate® glueable insert Ø23

Inox 316L

MSP23

- Glueable stainless steel plate with tapped insert or threaded stud
- Material:  
316L stainless steel

## Applications

- Industrial, transport, building, furnishings

## Info.


- Glue not supplied
- Not supplied individually, contact us for details





316L stainless steel




316L stainless steel

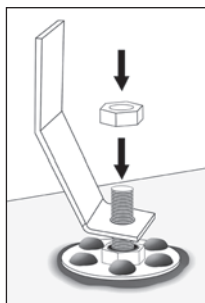


Typical application

  

Tapped

 

Nut

 

Thread

## DISCOUNTS

|       |      |      |      |            |
|-------|------|------|------|------------|
| Qty   | 1+   | 50+  | 100+ | 500+       |
| Disc. | List | -10% | -20% | On request |

| Part number    | A  | ØD | L   | Form   | Price each<br>1 to 49 |
|----------------|----|----|-----|--------|-----------------------|
| MSP23T-4-10/SS | 23 | M4 | 10  | Tapped | 6,13 €                |
| MSP23T-5-10/SS | 23 | M5 | 10  | Tapped | 6,33 €                |
| MSP23T-6-10/SS | 23 | M6 | 10  | Tapped | 6,55 €                |
| MSP23E-4-3/SS  | 23 | M4 | 3,2 | Nut    | 1,93 €                |
| MSP23E-5-4/SS  | 23 | M5 | 4   | Nut    | 1,97 €                |
| MSP23E-6-5/SS  | 23 | M6 | 5   | Nut    | 2,24 €                |
| MSP23F-4-16/SS | 23 | M4 | 16  | Thread | 2,05 €                |
| MSP23F-4-20/SS | 23 | M4 | 20  | Thread | 2,07 €                |
| MSP23F-5-12/SS | 23 | M5 | 12  | Thread | 2,07 €                |
| MSP23F-6-25/SS | 23 | M6 | 25  | Thread | 2,26 €                |

Fax

0 825 88 6000  
Service 0,15 € / min  
+ prix appel


cial2@hpceurope.com

HPC

SUPPLEMENT 2019


83
 
## Our other products



RPP8

 RPP heavy duty timing belt, RPP8



M1

Worm and wheel set, Bronze



CHT80

Asynchronous AC Motor 0.55 to 1.1kW, 0.55 to 1.1kW



GAL21

Conveyor wheel, Plastic



TUBE25\_25

Square Tube, Aluminium or Stainless steel



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



G0

Steel spur gear, Steel 20NCD2



BAN

Angular clamp, Universal



SCA

Flat cable clamp, Steel



CNA-CNG

Right angled mounting plate, Right angled mounting



PT882

Drive sprocket for slat top chain, Range 882



SCR

Suction cup threaded insert, Adaptor for insert

## Complementary products



MSP3815

Masterplate® glueable insert rectangular, rectangular with

tapped i...



MSP38

Masterplate®  
glueable insert Ø38,  
Cylindrical Ø38 with  
threaded s...



MSP3815

Masterplate®  
glueable insert  
rectangular,  
rectangular with nut



MSP3815

Masterplate®  
glueable insert  
rectangular,  
rectangular with

threaded...