

Cylindrical Master-Plate® glueable insert Ø38

MSP38

Inox 316L

- Glueable stainless steel plate with tapped insert or threaded stud
- Material:
316L stainless steel

Applications

- Industrial, transport, building, furnishings

Info.


- Glue not supplied
- Not supplied individually, contact us for details





316L stainless steel



316L stainless steel

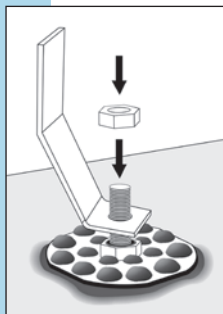

Exemple d'application

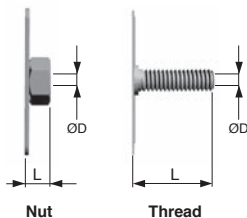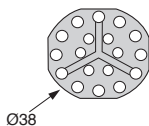

DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request

Part number	ØA	ØD	L	Form	Price each 1 to 49
MSP38EB-8-6/SS	38	M8	6,5	Blind tapped	3,11 €
MSP38E-8-6/SS	38	M8	6,5	Nut	3,11 €
MSP38F-6-40/SS	38	M6	40	Thread	3,11 €
MSP38F-8-40/SS	38	M8	40	Thread	3,51 €

Dimensions in mm

Our other products



SH0

Parallel axis helical gear, Machined plastic (delrin)



PRF_VTM

Hammerhead screw, Hammerhead screw



LRX

Linear roller slide, Chariot - from 9410 N to 101000 N




STL

Guidance brush - Rail, Rail




BPLE

Ball transfer unit push fit, Light

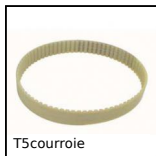

T5courroie

 T type timing belt, T5 Steel cored polyurethane



H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



BLHT70

Right angled gearbox, from 26 to 128 Nm



BTC

End cap for square tube, Standard



DIL

Lever operated locking bolt, lever clamp

Complementary products



MSP3815

Masterplate® glueable insert rectangular, rectangular with

tapped i...



Masterplate®
glueable insert
rectangular,
rectangular with nut



Masterplate®
glueable insert
rectangular,
rectangular with

threaded...



MSP38

Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
tapped ins...