

Rectangular Master-Plate® glueable insert

316L stainless steel

MSP

- Glueable stainless steel plate with tapped insert or threaded stud
- Material:
316L stainless steel

Applications

- Industrial, transport, building, furnishings



 
Info.

- Glue not supplied
- Not supplied individually, contact us for details

316L stainless steel



316L stainless steel

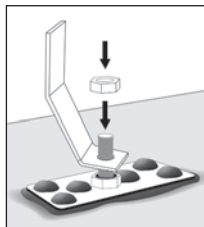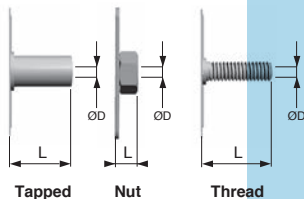

Typical application

DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request

Part number	A	B	ØD	L	Form	Price each 1 to 49
MSP3815T-6-5/SS	38	15	M6	5	Tapped	5,82 €
MSP3815E-5-4/SS	38	15	M5	4	Nut	2,05 €
MSP3815E-6-5/SS	38	15	M6	5	Nut	2,31 €
MSP3815E-8-6/SS	38	15	M8	6,5	Nut	2,50 €
MSP3815F-5-12/SS	38	15	M5	12	Thread	2,16 €
MSP3815F-5-16/SS	38	15	M5	16	Thread	2,21 €
MSP3815F-6-16/SS	38	15	M6	16	Thread	2,24 €
MSP3815F-6-20/SS	38	15	M6	20	Thread	2,29 €

Dimensions in mm


Fax **0 825 88 6000**
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

81

Our other products

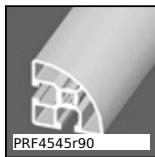

Standard aluminium profile, 45 x 45 mm - R90°



Spiral bevel gear, 1:1



Locking bolt, with T handle



Straight long link chain, Galvanised steel



Worm - precision range, Stainless steel



Worm and wheel gearbox, from 2.20 to 4.10 Nm



Structural fixing support, Stainless steel



Pad eye on mounting plate, Stainless steel



Spur gear, Moulded plastic (nylon)



Hypoid gearbox - Stainless steel, up to 350 Nm



Spring hinges, screwed



H Type Guide units, For Ø25 actuators

Complementary products



Masterplate® glueable insert, rectangular with tapped insert



Masterplate® glueable insert, cylindrical Ø38 with threaded stud



Masterplate® glueable insert, cylindrical Ø23 with threaded stud



Masterplate® glueable insert, rectangular with nut