

Master link assembly **high resistance**



MTT_{HR}

High strenght alloy steel

- Connecting link Rigging equipment

- Material:

High strenght alloy steel
grade 80 red painted

Stamping


- CE, SWL, manufacturer, grade

Info

- Generally conform to norm EN 1677- 4+A1

- The Breaking load is calculated by multipling
the WLL by a safety factor of 4"

High
resistance

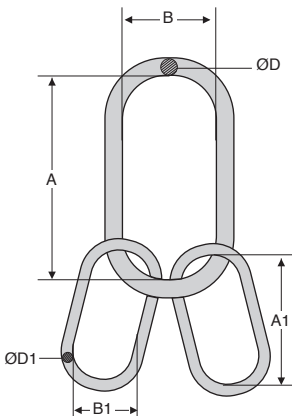

DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-20%	On request

Part number	WLL (kg)	A	B	ØD	A1	B1	ØD1	Weight (kg)	Stock*	Price each 1 to 5
MTT18-3150/HR	3,15	135	75	18	60	38	14	1,330		

*Dimensions in mm

Our other products



SCA
Flat cable clamp,
Steel



ACA
Steel splined shaft,
Steel



WJUM10
Drylin® W bearing
block, Slide



RDERSS
Stainless steel manual
rigging screw,
Stainless steel -
manual



RFK38B
Hypoid gearbox -
Stainless steel, up to
200 Nm



VAP
Magnetic stud with
central hole, With
central hole



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



DIL
Lever operated
locking bolt, lever
clamp



BPPEBLU
Ball transfer unit in
blue certified plastic,
for foodstuff sector



CM
Tools Hygienic Usit®
and Hygienic
Design®



J65
Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - Inline



BTE
Universal tension arm,
For standard
applications

Complementary products



ADL
Eye bolt high
resistance, alloy steel



ADL
Female eye bolt high
resistance, alloy steel



CRLHR
Female eye bolt high
resistance, strenght
alloy steel



ADL_M
Male eye bolt
conforms to DIN580,
Steel