

Cam follower without axial guide



NAST IKO

With interior ring


- For shaft diameters from 6mm to 50mm
- Without external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

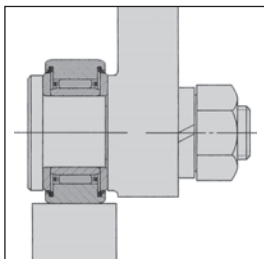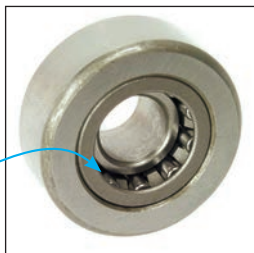

Typical application

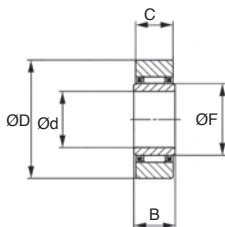

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 40+ |
| Disc. | List | -15% | -20% | On request |

| Part number | Ød | ØD | B | C | ØF | Static load Co (N) | Dynamic load C (N) | Max. load on rail (N) | Weight (g) | Stock* | Price each 1 to 5 |
|-------------|----|----|----|------|----|--------------------|--------------------|-----------------------|------------|--------|-------------------|
| NAST-6 | 6 | 19 | 10 | 9,8 | 10 | 4550 | 4160 | 3550 | 17,8 | ✓ | 13,98 € |
| NAST-8 | 8 | 24 | 10 | 9,8 | 12 | 5890 | 5650 | 3980 | 28,0 | ✓ | 15,40 € |
| NAST-10 | 10 | 30 | 12 | 11,8 | 14 | 9680 | 9790 | 5610 | 49,5 | ✓ | 24,57 € |
| NAST-12 | 12 | 32 | 12 | 11,8 | 16 | 10900 | 10500 | 5990 | 58,0 | - | 25,35 € |
| NAST-15 | 15 | 35 | 12 | 11,8 | 20 | 14300 | 12400 | 6550 | 62,0 | - | 26,22 € |
| NAST-17 | 17 | 40 | 16 | 15,8 | 22 | 20900 | 17600 | 10900 | 109,0 | ✓ | 27,95 € |
| NAST-20 | 20 | 47 | 16 | 15,8 | 25 | 24500 | 19400 | 12800 | 157,0 | ✓ | 31,32 € |
| NAST-25 | 25 | 52 | 16 | 15,8 | 30 | 28400 | 20800 | 14100 | 180,0 | ✓ | 33,58 € |
| NAST-30 | 30 | 62 | 20 | 19,8 | 38 | 45400 | 30500 | 22100 | 320,0 | - | 38,72 € |
| NAST-35 | 35 | 72 | 20 | 19,8 | 42 | 50600 | 32400 | 25700 | 440,0 | - | 39,84 € |
| NAST-40 | 40 | 80 | 20 | 19,8 | 50 | 61100 | 35900 | 26900 | 530,0 | ✓ | 49,68 € |
| NAST-45 | 45 | 85 | 20 | 19,8 | 55 | 66400 | 37400 | 28500 | 580,0 | - | 53,34 € |
| NAST-50 | 50 | 90 | 20 | 19,8 | 60 | 71700 | 38900 | 30200 | 635,0 | - | 60,68 € |

*Depending on availability - Dimensions in mm

Our other products



CLB_T

Die cast zinc clamping lever - male, Zamak



HW_HT

Half-rail guide, Rail



METC

Flanged sintered bronze bush, Self-lubricating sintered bronze



UTKpwc

Utilitrak® 3 wheels carriage, Polymer series V wheels



SERB

Cam latch, Cam latch



PRF1945

Standard aluminium profile, 19 x 45 mm



PTRSS

Idler chain sprocket, For hostile environments



Gal-cardan

Single universal joint eco series, Low duty



SH0

Parallel axis helical gear, Machined plastic



R203

Die spring ISO10243, Light



SDC_{SS}

Positioning sleeve for indexing pin, For pin



GAC

Lock for latch clamp, Strike plate

Complementary products



RNA_{ST}

Cam follower without axial guide, Without interior ring



CF

Cam follower, Standard - steel