

# Cam follower without axial guide



## NAST IKO

## With interior ring


- For shaft diameters from 6mm to 50mm
- Without external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

### Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

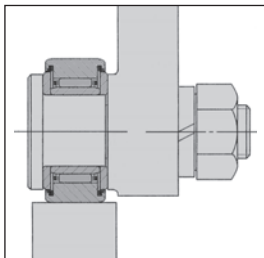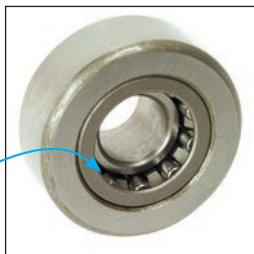

Typical application

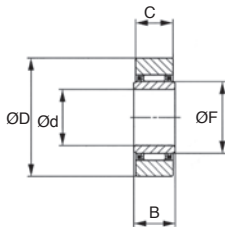

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	13,98 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	15,40 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	24,57 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	-	25,35 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	26,22 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	27,95 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	31,32 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	33,58 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	38,72 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	39,84 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	✓	49,68 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	53,34 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	60,68 €

\*Depending on availability - Dimensions in mm

## Our other products



P40  
Worm and wheel gear reducer, up to 18 Nm



CLLLLP  
Clevis components, long version, Steel - long version



 
RURp  
Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



DILC  
Indexing plunger with cam, with cam



ACLBDB  
Closing mechanism for aluminium profile, Dual ball catch



PM4  
Worm and wheel set, Machined plastic (delrin)



G2  
Steel spur gear, Steel 20NCD2



EHD06  
Internal epicyclic servo reducers, from 8 to 19 Nm



M0  
Worm and wheel set, Bronze



AFA  
Locking pin, with ring



PSPD18  
Flexible tube handle, Black PVC



CMM  
Male rod ends DIN ISO12240-4, Steel / bronze

## Complementary products



RNAS1  
Cam follower without axial guide, Without interior ring



CF  
Cam follower, Standard - steel