

Cam follower without axial guide


NAST IKO

With interior ring


- For shaft diameters from 6mm to 50mm
- Without external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

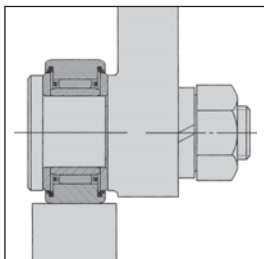

Typical application

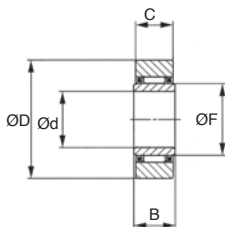

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	13,98 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	15,40 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	24,57 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	-	25,35 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	26,22 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	27,95 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	31,32 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	33,58 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	38,72 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	39,84 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	✓	49,68 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	53,34 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	60,68 €

*Depending on availability - Dimensions in mm

Our other products




Gal-cardan
Single universal joint
eco series, Low duty



PRF_BP
Doorstop for
aluminium profile,
Swing door stop



RPCpl
Swivel castor with
double brake, Steel -
Polyamide

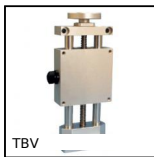


TBV
Manual lifting tables,
3kg




DOMI50
Accessories, Turntable



 MSP38
Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
threaded s...




TBV
Manual lifting tables,
20kg

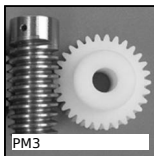

PM3
Worm and wheel set,
Machined plastic
(delrin)



 DOMI80
Accessories, Plate



GPLac
Brush, steel



DEP
Tools Hygienic Usit®
and Hygienic
Design®, Socket for
mounting Hyg...



EX
Optional shaft for E-
type gear reducers, E
Gearboxes single
sided ou...

Complementary products



RNAST
Cam follower without
axial guide, Without
interior ring



CF
Cam follower,
Standard - steel