

Cam follower without axial guide



NAST IKO

With interior ring


- For shaft diameters from 6mm to 50mm
- Without external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

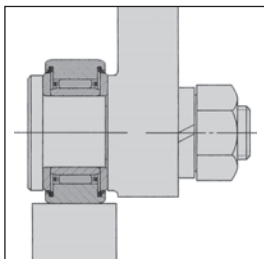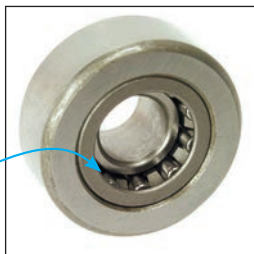

Typical application

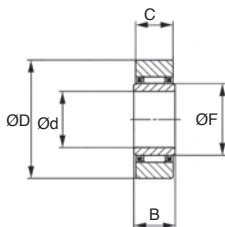


DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	13,98 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	15,40 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	24,57 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	-	25,35 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	26,22 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	27,95 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	31,32 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	33,58 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	38,72 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	39,84 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	✓	49,68 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	53,34 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	60,68 €

*Depending on availability - Dimensions in mm

Our other products

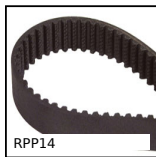

RPP14

RPP heavy duty timing belt, RPP14



BFM2

Flanged bronze nut, Bronze - 2 threads



CHB

Worm and wheel gear reducer, up to 41 Nm



BPF14s

Pressed stainless steel flange bearing, Stainless steel



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



FDS

Flexible drive shaft, Masterflex® Steel, with PVC casing



KBS_UU

Stainless steel closed precision linear bearing, Precision - stainle...



SLBS

Stainless steel indexing plunger, Stainless steel



BL15

Right angled gearbox, from 1.10 to 6 Nm



BCM_T

Driving collar, Driving collar



FBL6000_K1

Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide



RGS

Rotex® GS backlash free jaw coupling, from 0.5 to 190Nm

Complementary products



RNAS1

Cam follower without axial guide, Without interior ring



CF

Cam follower, Standard - steel