

Cam follower without axial guide



NAST IKO

With interior ring


- For shaft diameters from 6mm to 50mm
- With external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

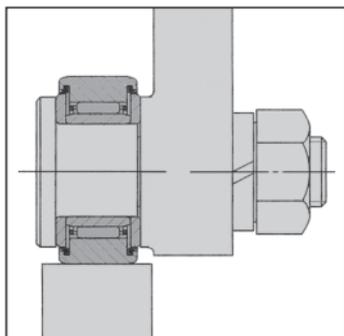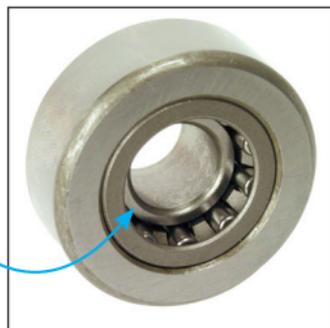

Typical application

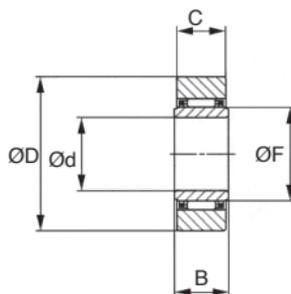

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	24,40 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	25,86 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	27,88 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	✓	29,33 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	29,78 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	30,56 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	34,23 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	36,66 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	42,28 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	44,32 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	-	55,07 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	59,19 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	67,27 €

*Depending on availability - Dimensions in mm



Cam follower without axial guide


Without interior ring

IKO RNAS


- For shaft diameters from 7mm to 60mm
- With external cylindrical cage
- Without wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6
- Shaft hardness: 58-64 HRC, Ra 0.2

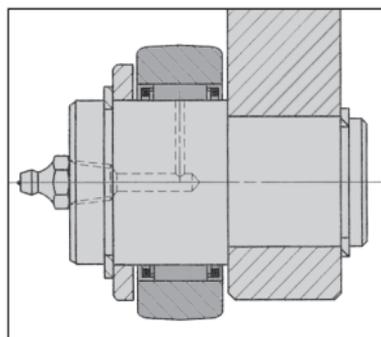

Typical application

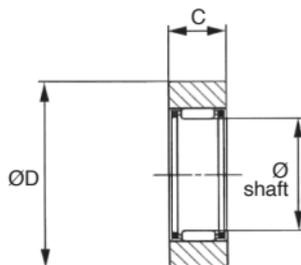

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Shaft Ø	ØD	C	Static load Co (N)	Dynamic load C (N)	Weight (g)	Stock*	Price each 1 to 5
RNAS-5	7	16	7,8	2390	2710	8,9	-	16,26 €
RNAS-6	10	19	9,8	4550	4160	13,9	✓	15,31 €
RNAS-8	12	24	9,8	5890	5650	23,5	✓	16,88 €
RNAS-10	14	30	11,8	9680	9790	42,5	-	20,02 €
RNAS-12	16	32	11,8	10900	10500	49,5	-	21,25 €
RNAS-15	20	35	11,8	14300	12400	50,0	✓	22,16 €
RNAS-17	22	40	15,8	20900	17600	90,0	-	22,10 €
RNAS-20	25	47	15,8	24500	19400	135,0	-	24,40 €
RNAS-25	30	52	15,8	28400	20800	152,0	-	27,38 €
RNAS-30	38	62	19,8	45400	30500	255,0	-	30,63 €
RNAS-35	42	72	19,8	50600	32400	375,0	-	33,85 €
RNAS-40	50	80	19,8	61100	35900	420,0	-	39,84 €
RNAS-45	55	85	19,8	66400	37400	460,0	-	40,88 €
RNAS-50	60	90	19,8	71700	38900	500,0	-	45,56 €

*Depending on availability - Dimensions in mm