

Square tube connector



NCTA
NCTB

Plastic

- For square tube $\varnothing 25 \times 25 \times 1.5$ mm
- Material: reinforced polyamide

Info.


- Not sold individually, please contact us for details

Accessories


- Structural tube TUBE
- Slide profiles PGT
- Support profiles PSP



Type A

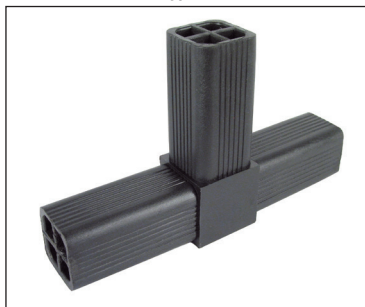

Type B

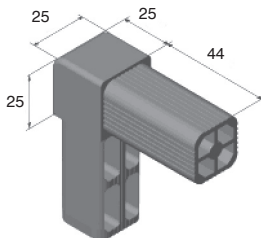

DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25A	0,05	A	✓	9,23 €
NCT25-25B	0,07	B	✓	10,06 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



Square tube connector

Plastic

NCT_C
NCT_D

- For square tube $\square 25 \times 25 \times 1.5 \text{ mm}$
- Material: reinforced polyamide

Info.



- Not sold individually, please contact us for details

Accessories

- Structural tube **TUBE**
- Slide profiles **PGT**
- Support profiles **PSP**



Type C

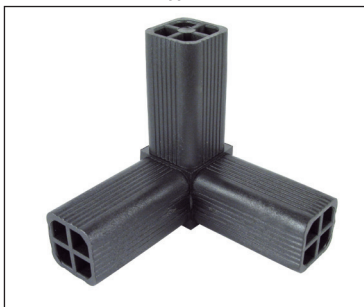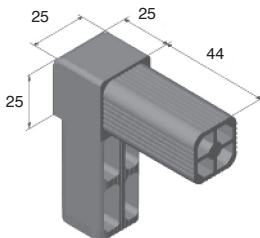

Type D

DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25C	0,09	C	✓	10,26 €
NCT25-25D	0,07	D	✓	10,06 €

*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15 €/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Square tube connector



NCT_E
NCT_F

Plastic

- For square tube $\square 25 \times 25 \times 1.5$ mm
- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

Accessories


- Structural tube TUBE
- Slide profiles PGT
- Support profiles PSP



Type E



Type F

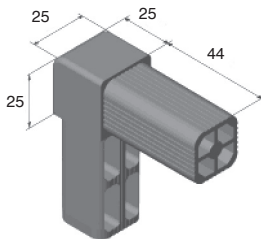

DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25E	0,09	E	✓	10,26 €
NCT25-25F	0,11	F	✓	10,69 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



Square tube connector

Plastic

NCTG
NCTH


- For square tube $\varnothing 25 \times 25 \times 1.5 \text{ mm}$
- Material: reinforced polyamide

Info.


- Not sold individually, please contact us for details

Accessories

- Structural tube **TUBE**
- Slide profiles **PGT**
- Support profiles **PSP**

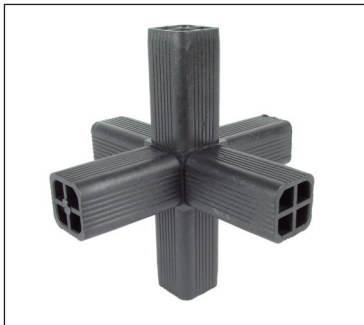

Type G

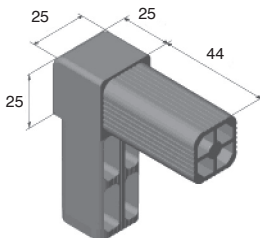

Type H

DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25G	0,13	G	-	11,54 €
NCT25-25H	0,05	H	✓	9,23 €

*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Our other products



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



CHB
Reaction arm, CHB
gear reducers
reaction arm



BABFCFO
Ball pin socket,
Mounting collar with
an oval flange



MAX26
Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm



CHAuss
Screwed hinge, 270°



PSG1HC
Skive hobbled spur
gears - precision
range, Case hardened
steel 20NCD2



COA-COG
Surface mounting
plate, Surface
mounting plate for
clevis



SHA
Handwheel without
handle, Polyamide



ACLCHAR
Hinge for aluminium
profile, With



NCT
Square tube
connector, Fixed



SCA
Flat cable clamp,
Steel



RBS
Dynamic washer
DIN2093, Steel

Complementary products



TUBE25_25
Square Tube,
Aluminium or
Stainless steel



NCT_AT
Variable angle
connector, Variable
angle



NCT
Square tube
connector, Fixed
angle



NCT
Square tube
connector, Fixed
angle