

# Square tube connector



NCTA  
NCTB

Plastic

- For square tube  $\varnothing 25 \times 25 \times 1.5 \text{ mm}$
- Material: reinforced polyamide

## Info.


- Not sold individually, please contact us for details

## Accessories


- Structural tube TUBE
- Slide profiles PGT
- Support profiles PSP



Type A

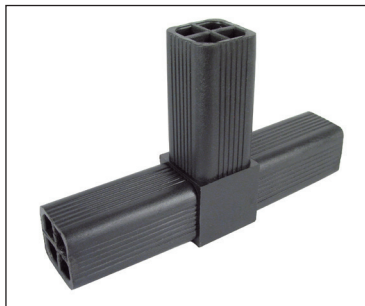

Type B

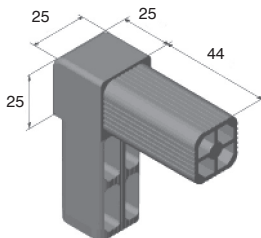

## DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25A	0,05	A	✓	9,23 €
NCT25-25B	0,07	B	✓	10,06 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



# Square tube connector

Plastic

NCT<sub>C</sub>  
NCT<sub>D</sub>

- For square tube  $\varnothing 25 \times 25 \times 1.5 \text{ mm}$
- Material: reinforced polyamide

## Info.


- Not sold individually, please contact us for details

## Accessories

- Structural tube **TUBE**
- Slide profiles **PGT**
- Support profiles **PSP**



Type C

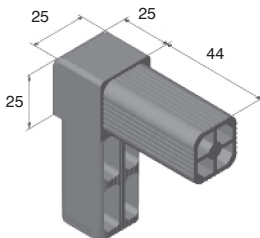

Type D

## DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25C	0,09	C	✓	10,26 €
NCT25-25D	0,07	D	✓	10,06 €

\*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15 €/mln + prix appel

cial2@hpceurope.com

WEB  
04/2020

**HPC**

# Square tube connector



NCT<sub>E</sub>  
NCT<sub>F</sub>

Plastic

- For square tube  $\square 25 \times 25 \times 1.5$  mm
- Material: reinforced polyamide

## Info.

- Not sold individually, please contact us for details

## Accessories


- Structural tube TUBE
- Slide profiles PGT
- Support profiles PSP



Type E



Type F

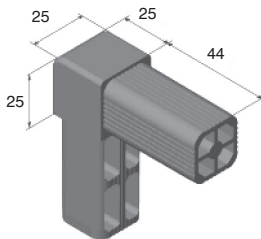

## DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25E	0,09	E	✓	10,26 €
NCT25-25F	0,11	F	✓	10,69 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



# Square tube connector

Plastic

NCTG  
NCTH


- For square tube  $\varnothing 25 \times 25 \times 1.5 \text{ mm}$
- Material: reinforced polyamide

## Info.


- Not sold individually, please contact us for details

## Accessories

- Structural tube **TUBE**
- Slide profiles **PGT**
- Support profiles **PSP**

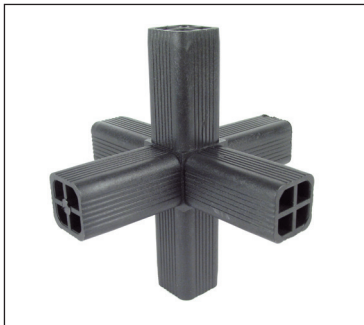

Type G

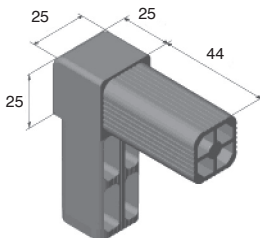

Type H

## DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25G	0,13	G	-	11,54 €
NCT25-25H	0,05	H	✓	9,23 €

\*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB  
04/2020

HPC

## Our other products



PSG2  
Spur gear - precision range, Case hardened steel 20NCD2



CAP820  
Slim slat top chain acetal, Narrow straight range 820



PCS62K  
Chain sprocket with hardened teeth, 15.875mm (DIN10B-1)



LQT  
Mechanical catch, Quick closing catch



BGC  
Oldham coupling, Clamp



PR125  
Articulated foot Ø123, Ø 123



PDD  
Actuating plunger, Non-rotating detector shaft



PP50  
Worm and wheel gear reducer, from 6.50 to 12.80 Nm




ZDB  
Machined plastic bevel gear, 2:1



AZY  
Cylindrical elasto mount, Steel



 ZG1  
Plastic spur gear, Machined plastic (delrin)



BH01  
Single housed bearing, Bearing fitted with adhesive

## Complementary products



NCT  
Square tube connector, Fixed angle



NCT  
Square tube connector, Fixed angle



TUBE25\_25  
Square Tube, Aluminium or Stainless steel



PGT  
Sliding profile, Sliding panel support