

Variable angle connector



NCTAT

Plastic

- For square tube $\varnothing 25 \times 25 \times 1.5$ mm
- Materials:
Body: reinforced polyamide
Screws: stainless steel

Info.


- Not sold individually, please contact us for details

Accessories


- Structural tube **TUBE**
- Slide profiles **PGT**
- Support profiles **PSP**



Adjustable

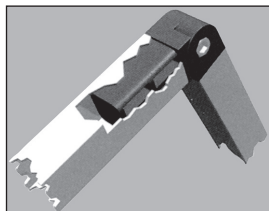

Example of use

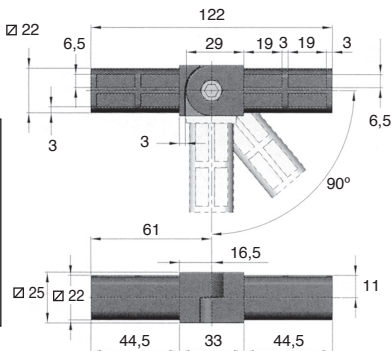

DISCOUNTS

Qty	1+	20+	30+
Disc.	List	-10%	On request

Part number	Weight (kg)	Type	Stock*	Price each 1 to 19
NCT25-25AT	0.12	AT	✓	11,23 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


Our other products



TOC
Short swivel head,
Short



 MSP23
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
tapped ins...



PM3
Worm and wheel set,
Bronze



RPCpl
Fixed castor with
plate, Steel -
Polyamide



GB-RA
Brass spur gear, Brass
CuZn39Pb3



ACLERP
Roller block for
aluminium profile,
With guide rail



HLUss
Spoked handwheel,
Stainless steel 316



TCC_SS
Stainless steel rigging
screw (hook/hook),
Stainless steel



EX
Optional shaft for E-
type gear reducers, E



T2
T type timing belt,
T2.5 Steel cored



VTHbr
Hexagonal headed
screw VTH - DIN933,
E



DCG
Suction cup, 2.5
bellows, nitrile

Complementary products



TUBE25_25
Square Tube,
Aluminium or
Stainless steel



NCT
Square tube
connector, Fixed
angle



NCT
Square tube
connector, Fixed
angle



NCT
Square tube
connector, Fixed
angle