

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied



Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes


Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

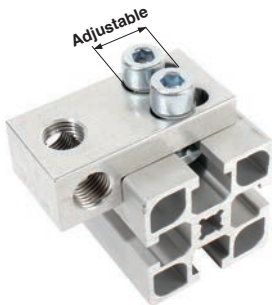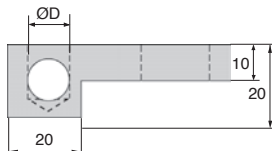

Typical mounting arrangement

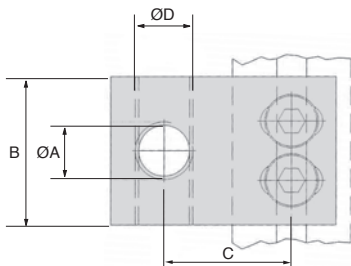

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

Our other products



LF

Precision locknut,
Precision locknut



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane



SLB

Indexing plunger,
stainless steel



PRF

Fixed levelling foot,
Flanged plate



UGPL

Actuator guide kit,
Long bearing



UCP

Cast iron pillow block
bearing, Cast iron



PT882

Drive sprocket for slat
top chain, Range 882



HRV

V-rail guidance
Simple Select®
system, Rail with
carriage



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with nut



G2

Steel spur gear, Steel
20NCD2



GMK17_R

Round guide, Round
guide for conical
profile



BPM_LOK

Long-Lok slotted
spring plunger with
ball tip, LONG-LOK -
Steel

Complementary products



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab