

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied




Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes


Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

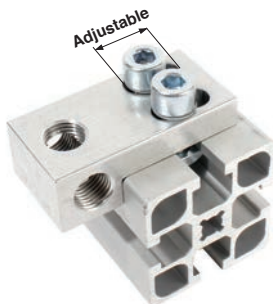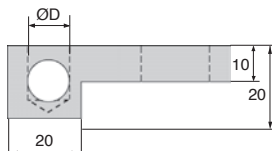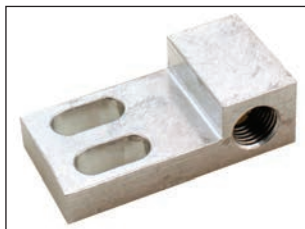

Typical mounting arrangement

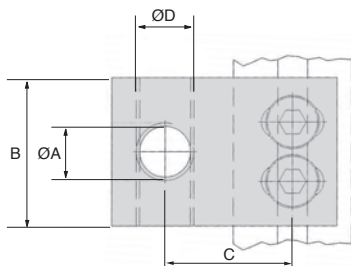


DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

 Our other products



Bearing block for leadscrew, Fixed Drylin® bearing block



Shaft locking washer, E clip



Universal 90° support clamp, Universal 90° support clamp



Quick fitting cable terminal, Fork



Articulated foot Ø83, Ø 83



T type timing belt per metre, T10 Steel cored polyurethane



Internal epicyclic servo reducers, from 20 to 50 Nm



Quick fitting threaded cable terminal, Cable terminal with threaded ...



Ball pin socket, Socket



Pull handle - Multi-sector, Tapped recessed insert



Conical flexible mount, Square base plate



Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78

Complementary products



Nut for aluminium profile, Steel square nut with tab