

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied



Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes


Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

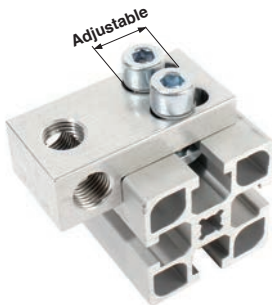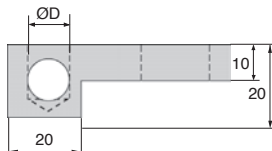

Typical mounting arrangement

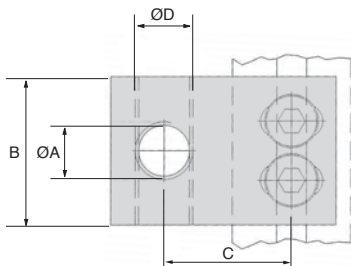

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

Our other products




WJUM16
Drylin® W bearing block, Slide



gt64
Rotating bent lever, Common applications



 CDPC
Flanged drill bushing, Steel



PF45
Worm and wheel gear reducer, up to 40 Nm



SH1
Parallel axis helical gear, Steel 20NCD2



D-PAR_SS
Stainless steel elasto mount, stainless steel



LWH
High rigidity linear slide, Rail - from 9320 N to 71300 N



 
PW_PWG15
Wheel - precision range, Bronze




NCT
Square tube connector, Fixed angle



UCFL_SS
Stainless steel flanged bearing, Stainless steel



 T5courroie
T type timing belt, T5 Steel cored polyurethane



H0
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)

Complementary products



PRF_ECL
Nut for aluminium profile, Steel square nut with tab