

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied



### Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes


### Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

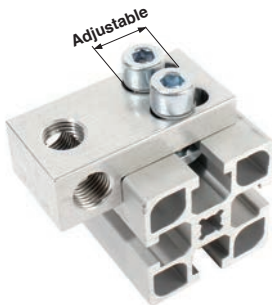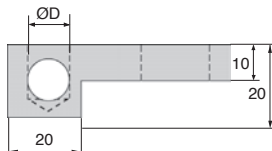

Typical mounting arrangement

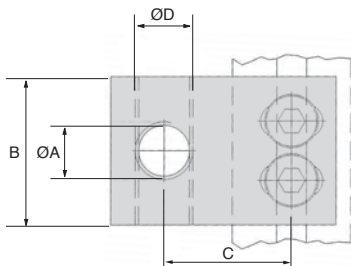

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

## Our other products



RFK58B

Hypoid gearbox -  
Stainless steel, up to  
500 Nm



PW\_PWG25

Worm - precision  
range, Steel



SDC5s

Positioning sleeve for  
indexing pin, For pin  
Ø4 to Ø12



SH5

Shoulder screw  
stainless steel 303,  
Stainless steel 303



SVR5

Screwjack with  
travelling nut, with  
moving nut



DCA

Suction cup, 1.5  
bellows, natural  
rubber



SA\_SAKH

Housing for linear  
bearing, Closed - light  
load



 
PDD

Actuating plunger,  
Non-rotating detector  
shaft



RTN

BoWex® curved tooth  
gear coupling, Nylon



PTA80

Articulated levelling  
foot, pressed base  
Ø80, 10000N



PPD

Indexing plunger for  
sheets, For sheet  
metal



PSG08

Spur gear - precision  
range, Case hardened  
steel 20NCD2

## Complementary products



PRF\_ECL

Nut for aluminium  
profile, Steel square  
nut with tab