

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied


Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes


Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

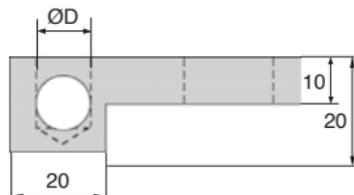

Typical mounting arrangement

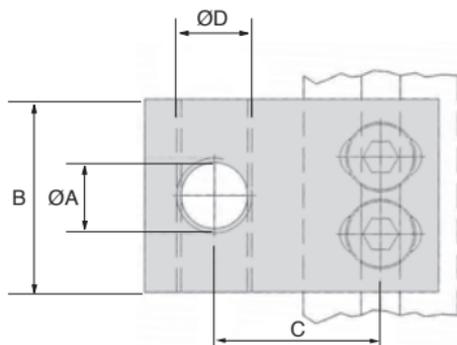

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

Our other products



PR882

Idler sprocket for slat top chain, Range 882



CQA30

Accessory for adjustment slide-system, 30



LVTMFC

Device for controlling limit switches, For mini-actuator LVT



RBNpl

Swivel castor with plate, Steel - rubber



CLASS

Stainless steel indexing handle - female, Stainless steel



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast



HLUT

Spoked handwheel with handle, Aluminium



BOXsap

Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752



PF70

Worm and wheel gear reducer, up to 164



ESCON

Speed controller 5A, 5 A



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



RCX-6

Spherical tilt washer - DIN6319, convex

Complementary products



PRF_ECL

Nut for aluminium profile, Steel square nut with tab