

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :
- Aluminium
- Fixing kit not supplied

Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes

Accessories



- PRF-ECLM8 nut
- M8 screw, length 20-22mm



Typical mounting arrangement



Typical mounting arrangement

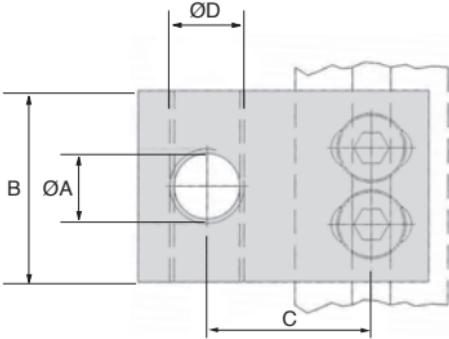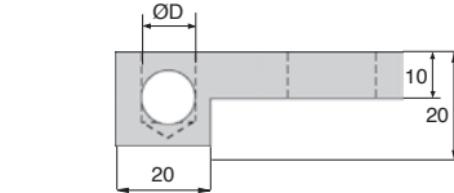

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |


| Part number | ØA | B | C | ØD | Weight (g) | Price each 1 to 9 |
|-------------|-------|----|-------|-------|------------|----------------------|
| NDS-1/4/C | G1/4" | 30 | 29-39 | G1/4" | 94 | 32,59 € |

Dimensions in mm

Our other products



Pull handle - Multi-sector, Tapped recessed insert

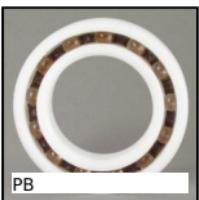

Plastic deep groove ball bearing, Plastic - glass balls material



Universal adjustable guide support bracket, Stainless steel



Stainless steel hexagonal headed thumb nut, Lobed handscrew



Sliding profile, Sliding panel support



Flat magnet, Flat magnet with thread



Internal epicyclic servo reducers, from 20 to 50 Nm



Die cast zinc clamping lever - male, Zamak



Accessories, Plate



T type timing belt per metre, T5 Steel cored polyurethane



HTD Heavy duty timing pulley, HTD5 Aluminium



Stainless steel bow shackle with eye bolt, Stainless steel

Complementary products



Nut for aluminium profile, Steel square nut with tab