

- Offers multiple connection possibilities for vacuum gripping system elements

- Material :

Aluminium

- Fixing kit not supplied





### Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes

### Accessories

- PRF-ECLM8 nut

- M8 screw, length 20-22mm

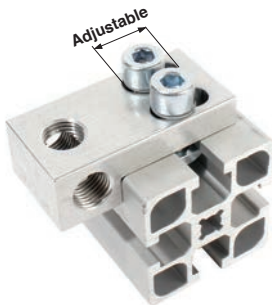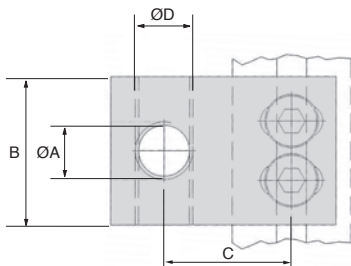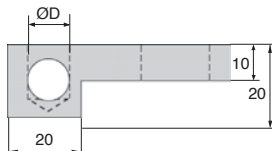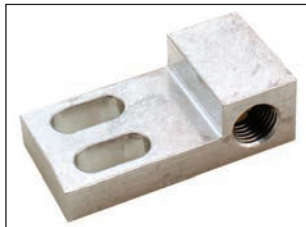

Typical mounting arrangement

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	32,59 €

Dimensions in mm

## Our other products



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel



CHAFR-MINI

Miniature friction hinge, Friction




FF40

Offset spur gear reducer, from 59 to 210 Nm



FF15

Offset spur gear reducer, from 2.20 to 10 Nm

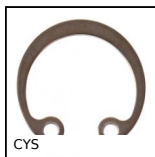

CYS

Internal circlip DIN472, internal DIN 472



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



KB\_WW

Closed linear precision bearing, Economy range



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



LRR

Spring loaded latch, Spring loaded latch



ZBconique

Machined plastic bevel gear, 1:1



J52

Spur gear coaxial gearbox, from 0.27 to 0.90 Nm - Inline



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions

## Complementary products



PRF\_ECL

Nut for aluminium profile, Steel square nut with tab