

Double cross clamp



NDS

Crossed or parallel

- For $\text{Ø}20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version



Parallel version

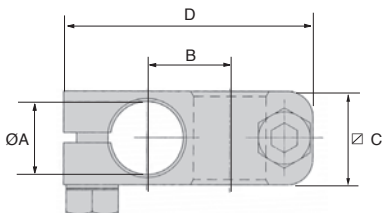

NDS-20/C

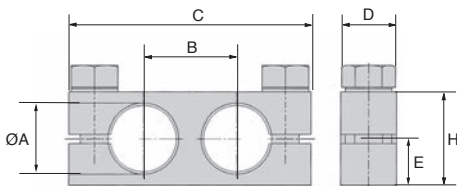

NDS-20/P

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	ØA	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	26,87 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	24,92 €

Dimensions in mm

Our other products



gt64

Rotating bent lever,
Common applications



RBGtc

Swivel castor with
central hole, Steel -
grey rubber - with
double b...



T5M T10M

T type timing belt per
metre, T5 Steel cored
polyurethane



CLR

Straight clevis,
Straight clevis for use
with a male clevis



DOMI50

Accessories, Fixing kit



PCS62

Chain sprocket - steel,
15.875 (DIN 10B-1)



 
UTKswcr

Utilitrac® 3 wheels
carriage, Steel roller
carriage




DIL

Lever operated
locking bolt, lever
clamp



MBrondelle

 Stop washer, Stop
washer MB




LAT2

2A motorised linear
actuator, 2 amperes



WW16

 Drylin® W slide, slide
assembly



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual

Complementary products



NDS20

Double cross clamp,
Parallel