

# Double cross clamp

New   Alu

## NDS

## Crossed or parallel

- For  $\text{Ø}20$  tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :  
Aluminium with steel screws

### Advantages


- Clip on, tool free assembly




Crossed version



Parallel version

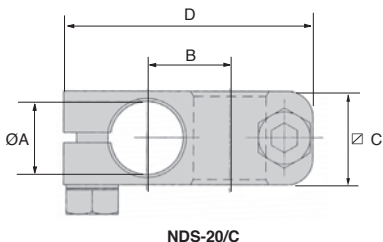

NDS-20/C

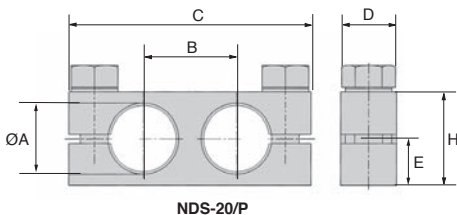

NDS-20/P

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	ØA	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	26,87 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	24,92 €

Dimensions in mm

## Our other products



TB\_ECO

Eco. range steel bevel gear, 3:1



SKM

Hexagonal steel nut, Steel - 1 thread



MLY

Bow shackle with eye bolt, Steel



 
PRF-SCREEN-1

Screen support, Basic support



SLH

Horizontal toggle clamp, Horizontal Lever Clamp - steel




H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PDM\_PDV

Detectable plastic palm grip, by metal detectors

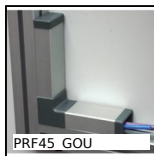

PRF45 GOU

Chute profile, Accessories



RJA11\_27

Sealing strip, Not clipping



VDSQ

Sliding lock adjustment system,



FAD

Threaded swivel feet, Swivel feet without



NPTF30

Fixed tube carrier, Fixed Ø14 to Ø20

## Complementary products



NDS20

Double cross clamp, Parallel