

Double cross clamp



NDS

Crossed or parallel

- For $\text{Ø}20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version



Parallel version

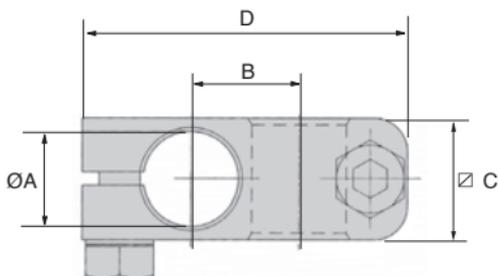

NDS-20/C

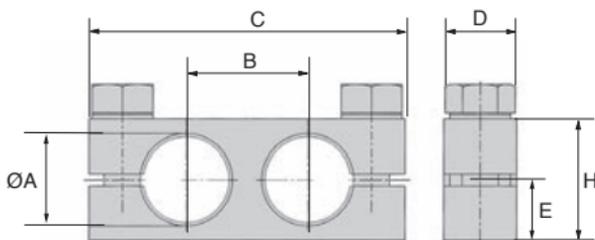

NDS-20/P

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	ØA	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	26,87 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	24,92 €

Dimensions in mm

Our other products



SHWbr
Washer - DIN125,
Brass



PRF1945
Standard aluminium
profile, 19 x 45 mm



SLH
Horizontal toggle
clamp, Horizontal
Lever Clamp - steel



RAG
Roller guide,



PX_PO
Carrying handle, back-
plated



BOXKK
Boxed set of
DIN6885A keys,
Boxed set - Steel or
stainless steel



MFBC
Flexible Bellows
coupling, Aluminium
and Bronze - with
clamping jaw



LVT
Miniature motorised
actuator 4A, 4 amperes




PGR
Folding revolving
handle for handwheel,



BHEX
Hexagonal cap, Black
technopolymer



BPTR
End cap for round
tube, Standard

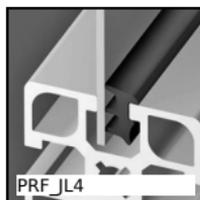

PRF_JL4
Lip seal for panel,
Door seal - Ø 4mm

Complementary products



NDS20
Double cross clamp,
Parallel