


Steel or stainless steel (A2)
with nylon insert

NINA
NIN

- Conforms to DIN 934
- Anti-vibration, self locking
- Nylon insert
- Material:
 - Chromed steel (Class 6.8)
 - Stainless steel (Class A2)
- Sold by the pack



steel or
stainless steel

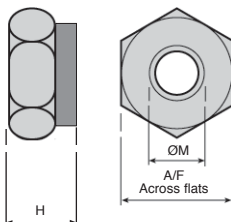

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	Thread ØM	Pitch	A/F Across flats	H	Qty per pack	Stock*	Price each 1 to 5
Steel							
NINA-5/B	M5	0,80	8,0	5,0	500	✓	8,72 €
NINA-6/B	M6	1,00	10,0	6,0	500	✓	11,97 €
NINA-8/B	M8	1,25	13,0	8,0	200	✓	10,20 €
NINA-10/B	M10	1,50	17,0	10,0	200	✓	22,61 €
NINA-12/B	M12	1,75	19,0	12,0	200	✓	34,07 €
NINA-16/B	M16	2,00	24,0	16,0	100	-	37,67 €
NINA-20/B	M20	2,50	30,0	20,0	50	-	31,56 €
Stainless steel							
NIN-3/B	M3	0,50	5,5	4,0	1000	✓	32,99 €
NIN-4/B	M4	0,70	7,0	5,0	1000	✓	31,40 €
NIN-5/B	M5	0,80	8,0	5,0	1000	✓	38,84 €
NIN-6/B	M6	1,00	10,0	6,0	500	✓	31,37 €
NIN-8/B	M8	1,25	13,0	8,0	200	✓	29,30 €
NIN-10/B	M10	1,50	17,0	10,0	200	✓	48,15 €
NIN-12/B	M12	1,75	19,0	12,0	100	✓	35,07 €
NIN-16/B	M16	2,00	24,0	16,0	50	✓	31,24 €
NIN-20/B	M20	2,50	30,0	20,0	25	-	71,96 €

*Depending to availability - Dimensions in mm

Our other products



VCMB
Dual-thread screw wood/metal, Stainless steel



PRF_GAL
Roller for aluminium profile, Fixing kit for roller eccentric



PENV
Recessed handle, screw fixing



PRDERS
Stainless steel manual rigging screw, Stainless steel - manual



CHTRP
Single and dual output gearboxes, Up to 9,1 Nm



ZBconique
Machined plastic bevel gear, 1:1



ERC
Quick fitting cable terminal, Eye version



PR821
Idler sprocket for slat top chain, Ranges 821 and 805



SBF
Sealed flange bearing unit for Food Industry, cover



CHM75
Worm and wheel gear reducer, up to 298 Nm



NCT
Square tube connector, Fixed angle



V3RA
3-spoked handwheel without handle, Polyamide

Complementary products



SHN
Hexagonal nut DIN934, A2 Stainless steel



WING
Manually tightened wing nut, Stainless steel DIN 314/315



CHCSS
Socket headed screw, Stainless steel - A2



VCMB
Dual-thread screw wood/metal, Stainless steel