


Steel or stainless steel (A2)
with nylon insert

NINA
NIN

- **Conforms to DIN 934**
- Anti-vibration, self locking
- Nylon insert
- Material:
 - Chromed steel (Class 6.8)
 - Stainless steel (Class A2)
- Sold by the pack



steel or
stainless steel

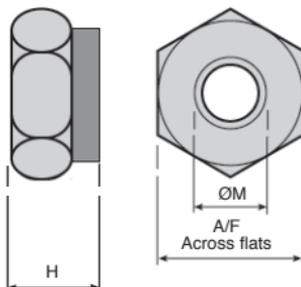

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	Thread ØM	Pitch	A/F Across flats	H	Qty per pack	Stock*	Price each 1 to 5
Steel							
NINA-5/B	M5	0,80	8,0	5,0	500	✓	8,72 €
NINA-6/B	M6	1,00	10,0	6,0	500	✓	11,97 €
NINA-8/B	M8	1,25	13,0	8,0	200	✓	10,20 €
NINA-10/B	M10	1,50	17,0	10,0	200	✓	22,61 €
NINA-12/B	M12	1,75	19,0	12,0	200	✓	34,07 €
NINA-16/B	M16	2,00	24,0	16,0	100	-	37,67 €
NINA-20/B	M20	2,50	30,0	20,0	50	-	31,56 €
Stainless steel							
NIN-3/B	M3	0,50	5,5	4,0	1000	✓	32,99 €
NIN-4/B	M4	0,70	7,0	5,0	1000	✓	31,40 €
NIN-5/B	M5	0,80	8,0	5,0	1000	✓	38,84 €
NIN-6/B	M6	1,00	10,0	6,0	500	✓	31,37 €
NIN-8/B	M8	1,25	13,0	8,0	200	✓	29,30 €
NIN-10/B	M10	1,50	17,0	10,0	200	✓	48,15 €
NIN-12/B	M12	1,75	19,0	12,0	100	✓	35,07 €
NIN-16/B	M16	2,00	24,0	16,0	50	✓	31,24 €
NIN-20/B	M20	2,50	30,0	20,0	25	-	71,96 €

*Depending to availability - Dimensions in mm

Our other products



GAL48_OMNI

Omni-directional roller, Omni-directional



PTA40ssEB

Articulated foot whit sheet metal base
Ø40, Ø 40



V3RA_PT

3-spoked handwheel with handle,
Polyamide



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



DILC

Indexing plunger with cam, with cam



GMK17_RG

Joint for guiding profile, Rounded



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



GMK17_R

Round guide, Round guide for conical profile



BPQ

Quadro linear ball bearing unit, Included 4 linear ball bearings



M0

Worm and wheel set, Hardened steel



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter

Complementary products



SHN

Hexagonal nut DIN934, Steel (Class 6/8)



WING

Manually tightened wing nut, Steel (ANSI B18-17)



VTH

Hexagonal headed bolts, Steel class 8.8



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts