

Steel or stainless steel (A2)  
with nylon insert

**NINA**  
**NIN**

- **Conforms to DIN 934**
- Anti-vibration, self locking
- Nylon insert
- Material:
  - Chromed steel (Class 6.8)
  - Stainless steel (Class A2)


### Info.

- Supplied by pack

### Accessories

- Box sets of self-locking nuts DIN985
- BOX-NINA**  
(tome 1 p.655)

Steel or  
stainless steel

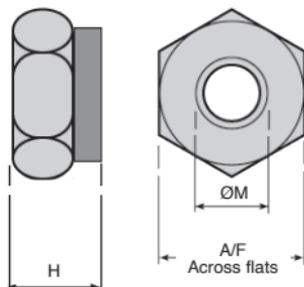

### DISCOUNTS

N° packets	1+	6+	11+
Discounts	List	-10%	On request

Part number	Thread ØM	Pitch	A/F Across flats	H	Qty. per pack	Stock*	Price per packet
<b>Steel</b>							
NINA-5/B	M5	0,80	8,0	5,0	500	✓	9,83 €
NINA-6/B	M6	1,00	10,0	6,0	500	✓	13,81 €
NINA-8/B	M8	1,25	13,0	8,0	200	✓	11,05 €
NINA-10/B	M10	1,50	17,0	10,0	200	✓	17,87 €
NINA-12/B	M12	1,75	19,0	12,0	200	✓	36,04 €
NINA-16/B	M16	2,00	24,0	16,0	100	-	28,29 €
NINA-20/B	M20	2,50	30,0	20,0	50	-	32,55 €
<b>Stainless steel</b>							
NIN-3/B	M3	0,50	5,5	4,0	1000	✓	36,78 €
NIN-4/B	M4	0,70	7,0	5,0	1000	✓	35,03 €
NIN-5/B	M5	0,80	8,0	5,0	1000	✓	43,32 €
NIN-6/B	M6	1,00	10,0	6,0	500	✓	35,00 €
NIN-8/B	M8	1,25	13,0	8,0	500	✓	61,98 €
NIN-10/B	M10	1,50	17,0	10,0	200	✓	33,14 €
NIN-12/B	M12	1,75	19,0	12,0	200	✓	39,12 €
NIN-16/B	M16	2,00	24,0	16,0	100	-	44,20 €
NIN-20/B	M20	2,50	30,0	20,0	50	-	55,25 €

\*Depending to availability - Dimensions in mm