


Steel or stainless steel (A2)
with nylon insert

NINA
NIN

- Conforms to DIN 934
- Anti-vibration, self locking
- Nylon insert
- Material:
 - Chromed steel (Class 6.8)
 - Stainless steel (Class A2)
- Sold by the pack



steel or
stainless steel

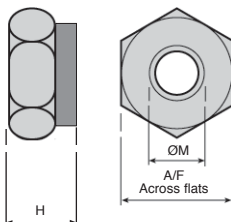

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	Thread ØM	Pitch	A/F Across flats	H	Qty per pack	Stock*	Price each 1 to 5
Steel							
NINA-5/B	M5	0,80	8,0	5,0	500	✓	8,72 €
NINA-6/B	M6	1,00	10,0	6,0	500	✓	11,97 €
NINA-8/B	M8	1,25	13,0	8,0	200	✓	10,20 €
NINA-10/B	M10	1,50	17,0	10,0	200	✓	22,61 €
NINA-12/B	M12	1,75	19,0	12,0	200	✓	34,07 €
NINA-16/B	M16	2,00	24,0	16,0	100	-	37,67 €
NINA-20/B	M20	2,50	30,0	20,0	50	-	31,56 €
Stainless steel							
NIN-3/B	M3	0,50	5,5	4,0	1000	✓	32,99 €
NIN-4/B	M4	0,70	7,0	5,0	1000	✓	31,40 €
NIN-5/B	M5	0,80	8,0	5,0	1000	✓	38,84 €
NIN-6/B	M6	1,00	10,0	6,0	500	✓	31,37 €
NIN-8/B	M8	1,25	13,0	8,0	200	✓	29,30 €
NIN-10/B	M10	1,50	17,0	10,0	200	✓	48,15 €
NIN-12/B	M12	1,75	19,0	12,0	100	✓	35,07 €
NIN-16/B	M16	2,00	24,0	16,0	50	✓	31,24 €
NIN-20/B	M20	2,50	30,0	20,0	25	-	71,96 €

*Depending to availability - Dimensions in mm

Our other products



WJUM16
Drylin® W modular guidance, Slide



GSI
Gas spring, Stainless steel



SER
Hinged door accessories, Magnetic doorstop



PRF_GAL
Roller for aluminium profile, Hollow roller ø12



BUC00031SS
Splined collar, Stainless steel



DOG319
DC Motor and gearbox combination, from 4 to 9 Nm



 
PW_PWG2
Worm - precision range, Steel



TPEpbd
Wheel, Swivel with brake



LSAG
Splined ball shaft, Rail - from 514 N to 15386 N



G0
Spur gear, Steel 20NCD2



CHC
Socket headed screw CHC - DIN 912, Steel class 12.19



KB_WW
Linear bearing, Economy range

Complementary products



SHN
Six-sided nut - DIN 934, A2 Stainless steel



WING
Manually tightened wing nut, Stainless steel DIN 314/315



CHCSS
Socket headed screw CHC - DIN 912, Stainless steel - A2



VCMB
Dual-thread screw wood/metal, Stainless steel