


Steel or stainless steel (A2)  
with nylon insert

**NINA**  
**NIN**

- Conforms to DIN 934
- Anti-vibration, self locking
- Nylon insert
- Material:
  - Chromed steel (Class 6.8)
  - Stainless steel (Class A2)
- Sold by the pack



steel or  
stainless steel

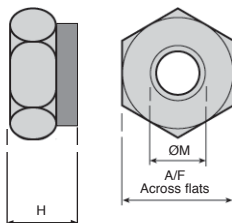

## DISCOUNTS

|           |      |      |            |
|-----------|------|------|------------|
| N° packs  | 1+   | 6+   | 11+        |
| Discounts | List | -10% | On request |

| Part number            | Thread<br>ØM | Pitch | A/F<br>Across flats | H    | Qty per pack | Stock* | Price each<br>1 to 5 |
|------------------------|--------------|-------|---------------------|------|--------------|--------|----------------------|
| <b>Steel</b>           |              |       |                     |      |              |        |                      |
| NINA-5/B               | M5           | 0,80  | 8,0                 | 5,0  | 500          | ✓      | 8,72 €               |
| NINA-6/B               | M6           | 1,00  | 10,0                | 6,0  | 500          | ✓      | 11,97 €              |
| NINA-8/B               | M8           | 1,25  | 13,0                | 8,0  | 200          | ✓      | 10,20 €              |
| NINA-10/B              | M10          | 1,50  | 17,0                | 10,0 | 200          | ✓      | 22,61 €              |
| NINA-12/B              | M12          | 1,75  | 19,0                | 12,0 | 200          | ✓      | 34,07 €              |
| NINA-16/B              | M16          | 2,00  | 24,0                | 16,0 | 100          | -      | 37,67 €              |
| NINA-20/B              | M20          | 2,50  | 30,0                | 20,0 | 50           | -      | 31,56 €              |
| <b>Stainless steel</b> |              |       |                     |      |              |        |                      |
| NIN-3/B                | M3           | 0,50  | 5,5                 | 4,0  | 1000         | ✓      | 32,99 €              |
| NIN-4/B                | M4           | 0,70  | 7,0                 | 5,0  | 1000         | ✓      | 31,40 €              |
| NIN-5/B                | M5           | 0,80  | 8,0                 | 5,0  | 1000         | ✓      | 38,84 €              |
| NIN-6/B                | M6           | 1,00  | 10,0                | 6,0  | 500          | ✓      | 31,37 €              |
| NIN-8/B                | M8           | 1,25  | 13,0                | 8,0  | 200          | ✓      | 29,30 €              |
| NIN-10/B               | M10          | 1,50  | 17,0                | 10,0 | 200          | ✓      | 48,15 €              |
| NIN-12/B               | M12          | 1,75  | 19,0                | 12,0 | 100          | ✓      | 35,07 €              |
| NIN-16/B               | M16          | 2,00  | 24,0                | 16,0 | 50           | ✓      | 31,24 €              |
| NIN-20/B               | M20          | 2,50  | 30,0                | 20,0 | 25           | -      | 71,96 €              |

\*Depending to availability - Dimensions in mm


## Our other products



CLASS  
Stainless steel indexing handle - female, Stainless steel



EBC  
Cap nut Hygienic Design®, Compact

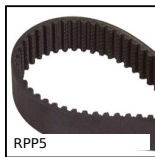

RPP5  
RPP heavy duty timing belt, RPP5



AT5M AT10M  
AT type timing belt per metre, AT5 Steel cored polyurethane



PSG15  
Spur gear - precision range, Case hardened steel 20NCD2



MCLred  
Reducing sleeve female/female, Cylindrical - stainless steel



HTD3M\_09  
HTD Heavy duty timing pulley, HTD3 Aluminium



PRF\_PGN  
Door handle for aluminium profile, Handle with lock suitable



SHN  
Hexagonal nut DIN934, Steel (Class 6|8)



PHTss  
Pull handle, Up to 250 °C



CHT  
Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



CHML40  
Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter

## Complementary products



SHN  
Hexagonal nut DIN934, Steel (Class 6|8)



WING  
Manually tightened wing nut, Steel (ANSI B18-17)



VTH  
Hexagonal headed bolts, Steel class 8.8



BOX-NINA  
Self locking nut - DIN985, Box set of steel nuts