

Multiple junction clamp



NJM

For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic


Colour: dark grey

Screw: resistance class 5.8, yellow chromate plated steel


Body: high-resistance anodised aluminium

Advantages

- Parallel mounting arrangement can be used to strengthen a structure
- Additional holes in body allow orthogonal joints to be assembled

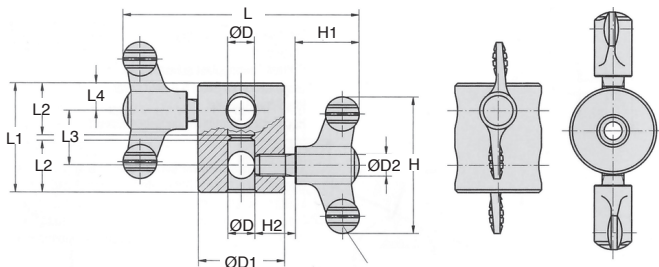

Positions:

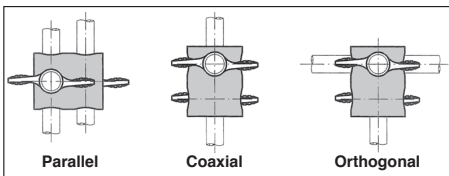

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

*Depending on availability - Dimensions in mm

Our other products



SUPCC
Self-centering
clamping hub steel,
With lock nut



DGSA
Male rod ends , Steel /
steel - Economy range



SLH
Horizontal toggle
clamp, Horizontal
Lever Clamp - steel



D19 D29
Compression springs
in metre length steel,
by the metre



SLB
Indexing plunger,
stainless steel



PRF_ROUL
Castor for aluminium
profile, No brake




GP75
Spring loaded toggle
latch, Standard
(GP75)



ACL-FPA
Panel mounting block
for aluminium
structures, Angular
connector



 UCP_SS
Stainless steel pillow
block bearing,
Stainless steel



ACL-PR
Joining plate for
aluminium profile,
Right angled



RGS
Rotex® GS backlash
free jaw coupling,
from 0.5 to 190Nm



UGH16
H Type Guide units,
For Ø12 and Ø16
actuators

Complementary products



NSA
Adjustable clamp,
Articulated



NSR
Adjustable clamp,
Adjustable