

Multiple junction clamp



NJM

For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic



Colour: dark grey

Screw: resistance class 5.8, yellow chromate plated steel


Body: high-resistance anodised aluminium

Advantages

- Parallel mounting arrangement can be used to strengthen a structure
- Additional holes in body allow orthogonal joints to be assembled

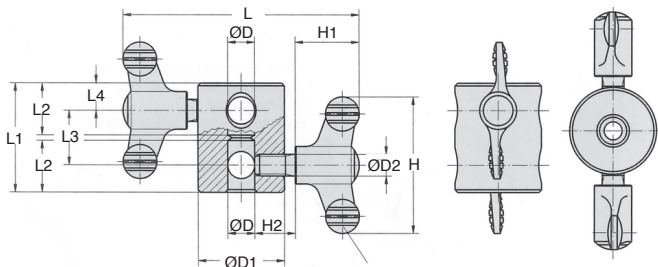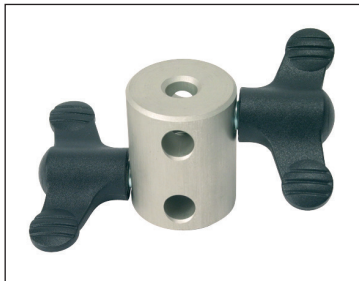

Positions:

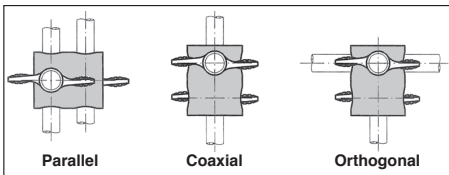

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



P55
Worm and wheel gear reducer, up to 57 Nm



PM2
Worm, Non hardened steel



AT10-BAR
AT type tooth bar stock, AT10



DOMI50
Accessories, Fixing kit



RFK28C
Hypoid gearbox - Stainless steel, up to 130 Nm



BSP
Compact precision slide, from 156 N to 980 N



RPCpl
Swivel castor with double brake, Steel - Polyamide



PAMF80EB
Articulated foot with sheet metal base Ø80, Articulated foot



CHML50
Worm and wheel gear reducer, up to 107



MRA
Quick link, Steel



M2
Wormwheel, Bronze



PRF4590
Standard aluminium profile, 45 x 90 mm

Complementary products



NSA
Adjustable clamp, Articulated



NSR
Adjustable clamp, Adjustable