

# Multiple junction clamp



## NJM

## For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic

Colour: dark grey


Screw: resistance class 5.8, yellow chromate plated steel

Body: high-resistance anodised aluminium




### Advantages

- Parallel mounting arrangement can be used to strengthen a structure
- Additional holes in body allow orthogonal joints to be assembled

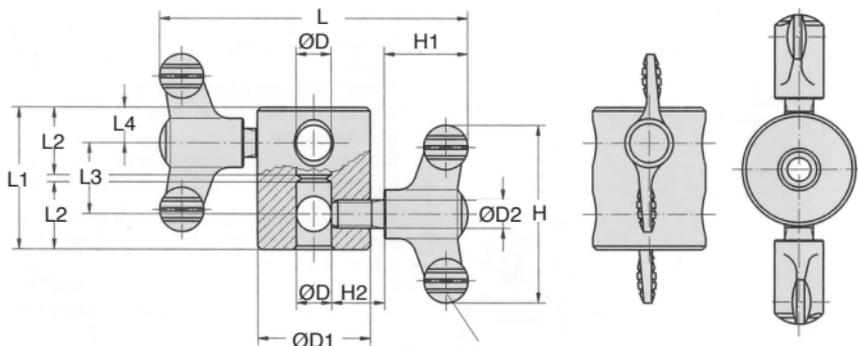

Positions:

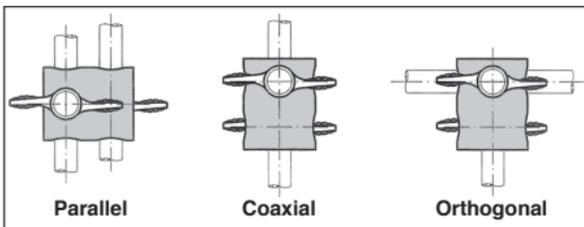

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

\*Depending on availability - Dimensions in mm

## Our other products



FGWA

End support, With base



BMM

Knurled knob - male, Knurled



CAP805

Slat top chain stainless steel, Large range 805



ACLCHAR

Hinge for aluminium profile, With elongated holes



HSE-HSB

Hexagonal spacer, Steel



WING

Manually tightened wing nut, Steel (ANSI B18-17)



PSPE20

Conical flexible shaft handle Ø20, Black PVC



BPLE

Ball transfer unit push fit, Light



TBV

Manual lifting tables, 3kg




SA\_SAKH

Housing for linear bearing, Closed - light



HTD8M\_30

HTD Heavy duty timing pulley, HTD8

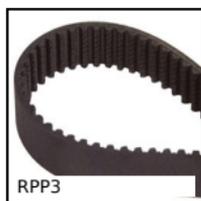

RPP3

RPP heavy duty timing belt, RPP3

## Complementary products



NSA

Adjustable clamp, Articulated



NSR

Adjustable clamp, Adjustable