

Multiple junction clamp



NJM

For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic



Colour: dark grey

Screw: resistance class 5.8, yellow chromate plated steel


Body: high-resistance anodised aluminium

Advantages

- Parallel mounting arrangement can be used to strengthen a structure
- Additional holes in body allow orthogonal joints to be assembled

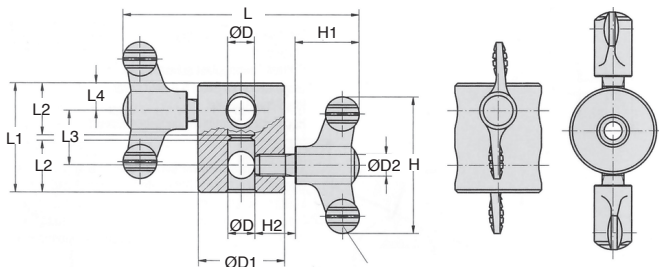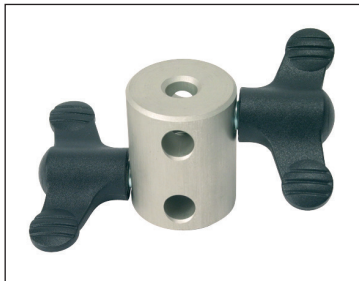

Positions:

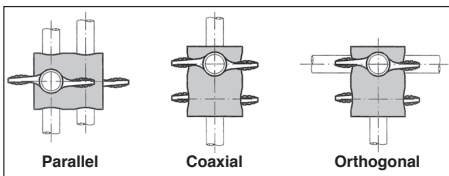

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



GAE
Decorative rigid latch clamp, without key



KKB-AR
Linear bearing with inclined ball tracks, Standard loads / -20° +20...



V3RA
3-spoked handwheel without handle, Polyamide



IBJ
180° ball and socket joints, Steel



RURt
Swivel castor with central hole, Polyurethane - Aluminium rim (Free)



PCS37SS
Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)




PCS37K
Chain sprocket with hardened teeth, 9.525mm (DIN06B-1)




DOMI120
Connecting kits, XZ linking kit



CCLSS
Stainless steel wire thimble, Stainless

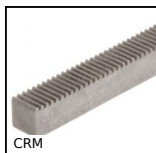

CRM
Moulded nylon rack, Nylon

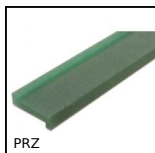

PRZ
Wear strip for slat top chain, Z profile to be



PRF45 GOU
Chute profile, Accessories

Complementary products



NSA
Adjustable clamp, Articulated



NSR
Adjustable clamp, Adjustable