

# Multiple junction clamp



## NJM

## For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: resistance class 5.8, yellow chromate plated steel


Body: high-resistance anodised aluminium

### Advantages


- Parallel mounting arrangement

can be used to strengthen a structure

- Additional holes in body allow orthogonal joints to be assembled

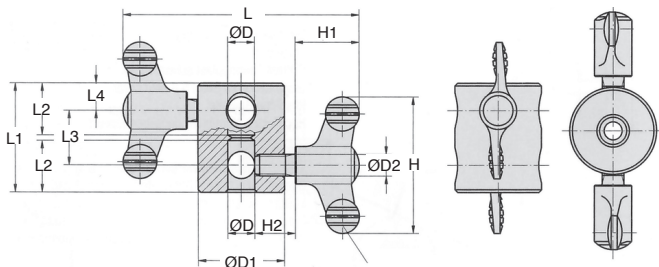

Positions:

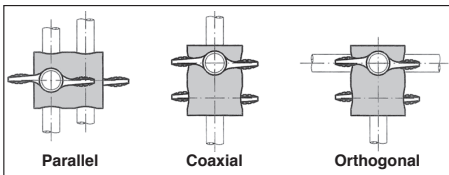

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

\*Depending on availability - Dimensions in mm

## Our other products



G1

Steel spur gear, Steel  
20NCD2



CAP882

Flexible slat top chain  
acetal, Large range  
882



KB\_WW

Closed linear  
precision bearing,  
Economy range



CHAE6555

Decorative screwed  
hinge, Aluminium



MHWC

Double-disc flexible  
coupling, Double disk



CAP805

Slat top chain  
stainless steel, Large  
range 805



PGMSS

Stainless steel pull  
handle, Stainless steel



AT5P\_AT10P

Connecting plate for  
AT type timing belts,  
AT10



AT5M AT10M

AT type timing belt  
per metre, AT10 Steel



CHM110

Worm and wheel gear  
reducer, up to 980



EAR

Bearing locknut, Self  
locking locknut - nylon



TCL-ECL

Adjusting nut, Fine  
thread

## Complementary products



NSA

Adjustable clamp,  
Articulated



NSR

Adjustable clamp,  
Adjustable