

Multiple junction clamp



NJM

For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: resistance class 5.8, yellow chromate plated steel


Body: high-resistance anodised aluminium

Advantages


- Parallel mounting arrangement

can be used to strengthen a structure

- Additional holes in body allow orthogonal joints to be assembled

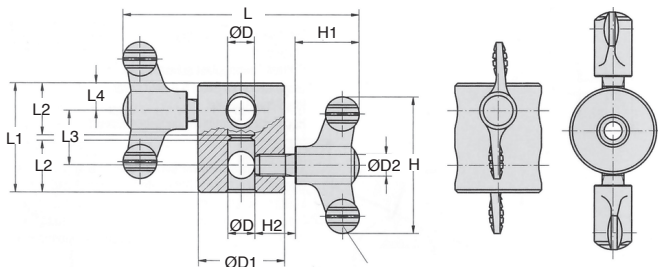

Positions:

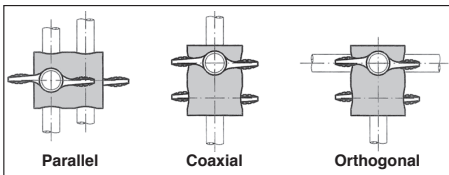

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 4
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	-	44,11 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	46,17 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	-	52,79 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	67,34 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products




PRS30

Stainless steel articulated foot Ø30, Ø 30



CFES

Eccentric cam follower, Eccentric

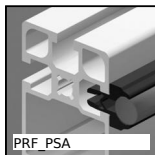

PRF_PSA

Shaft support for aluminium profile, Shaft support



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



DB

Steel bevel gear, 2:1



GE1006

Elastic ringed latch, Hooks into a slot



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls



ZG2

Plastic spur gear, Machined plastic



ERC

Quick fitting cable terminal, Eye version



PSG15

Spur gear - precision range, Pre-hardened



PM3

Worm and wheel set, Hardened steel

Complementary products



NSA

Adjustable clamp, Articulated



NSR

Adjustable clamp, Adjustable