





NK17 NW17


Loads up to 50N

- Linear rail with polymer slide
- Reduced size (both height and surface)
- Dry working, no maintenance required
- Not affected by dust
- Corrosion-resistant
- Reduced coefficient of friction means wear is reduced
- Reduced weight thanks to use of a combination of aluminium and plastic
- Very high speeds and acceleration possible
- Replaceable sliding parts in iglidur® J
- Materials:
 - Slide body: Plastic
 - Rails: Anodised aluminium
- Symmetrical hole pattern, C5=C6

Small but effective

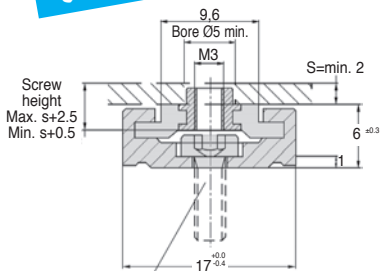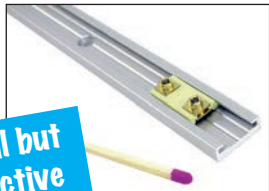

For M3 screw
DIN 7984 DIN
6912 DIN 84
EN ISO 1707

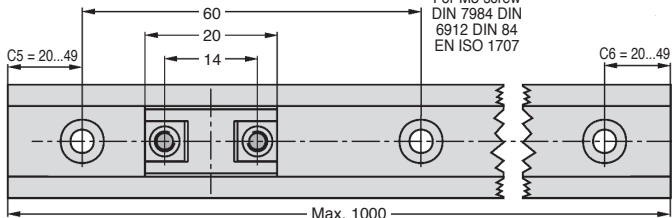


DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-6%	On request

Part number	Type	Weight (g)	Stock*	Price each 1 to 4
NK02-17-1000	1 Rail (1000mm) + 1 slide	151,7	✓	47,80 €
NW02-17	1 slide only	1,7	✓	4,25 €

*Depending on availability - Dimensions in mm

 Our other products



PF45
Worm and wheel gear reducer, up to 40 Nm



CQA20
Accessory for adjustment slide-system, 20



HW_HT
Half-rail guide, Rail



PITA
Locking bolt, with T handle



AT5courroie
AT type timing belt, AT5 Steel cored polyurethane



G4
Steel spur gear, Steel 20NCD2



PW_PWG1
Wheel - precision range, Bronze



GARDLL
Mounting sleeve for lock pin, Nickel-plated steel or Stainless steel



BPPE
Ball transfer unit push fit, Light



SMS
Spiral bevel gear, 1:1



GCL
Linear ball slide Eco Range, economy range



NPTF20
Spacer for tube carrier, Fixing accessory Ø10 to Ø14

Complementary products



NSKB
Drylin® Rail end cap, Rail end cap