





NK40 NW40

Load up to 700N



- Linear rail with polymer slide
- Reduced size (both height and surface)
- Dry working, no maintenance required
- Not affected by dust
- Corrosion-resistant
- Reduced coefficient of friction means wear is reduced
- Reduced weight thanks to use of a combination of aluminium and plastic
- Very high speeds and acceleration possible
- Replaceable sliding parts in iglidur® J
- Materials:
 - Slide body: Zinc
 - Rails: Anodised aluminium
- Symmetrical hole pattern, C5=C6

Small but effective

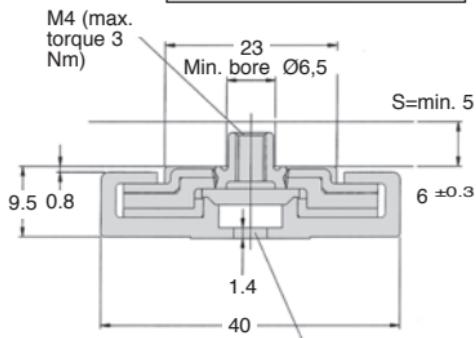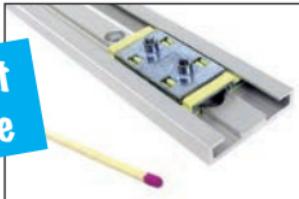

Options

- Rail length up to 3000mm max.

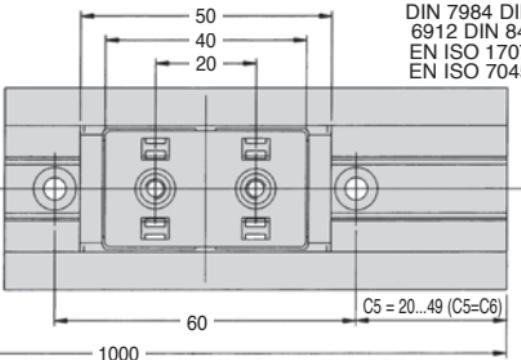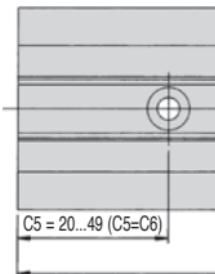

For M4 screw
DIN 7984 DIN
6912 DIN 84
EN ISO 1707
EN ISO 7045

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-6%	On request

Part number	Type	Weight (g)	Stock*	Price each 1 to 4
NK02-40-1000	1 Rail (1000mm) + 1 slide	480	✓	78,21 €
NW02-40	1 slide only	30	✓	8,93 €

*Depending on availability - Dimensions in mm


Our other products



LRX



MHPGR

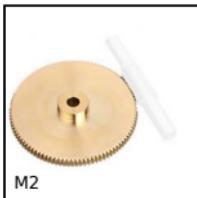

M2



CHAC4040NP

Linear roller slide,
Chariot - from 9410 N
to 101000 N

Arm with folding
rotating handle,

Worm and wheel set,
Bronze

Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...



GBS



LRX



KSTM

Nut for ballscrew,
Flanged ballscrew nut

Linear roller slide, Rail
- from 9410 N to
101000 N

Igubal® pillow block
bearing, Polymer

Automatic chain
tensioner, With
stainless steel
sprocket



Axle for tensioner
pulley, Shaft



Worm - precision
range, Steel



Connecting plate for T
type timing belts, T5



Eco range Spur gear,
Steel C45

Complementary products



NSKB
Drylin® Rail end cap,
Rail end cap