


NK40 NW40


Load up to 700N

- Linear rail with polymer slide
- Reduced size (both height and surface)
- Dry working, no maintenance required
- Not affected by dust
- Corrosion-resistant
- Reduced coefficient of friction means wear is reduced
- Reduced weight thanks to use of a combination of aluminium and plastic
- Very high speeds and acceleration possible
- Replaceable sliding parts in iglidur® J
- Materials:
 - Slide body: Zinc
 - Rails: Anodised aluminium
- Symmetrical hole pattern, C5=C6

Small but effective

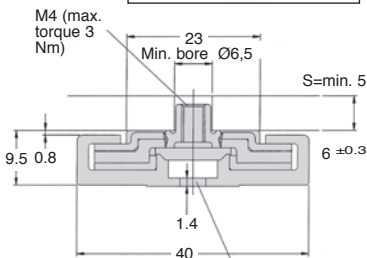

For M4 screw
DIN 7984 DIN
6912 DIN 84
EN ISO 1707
EN ISO 7045

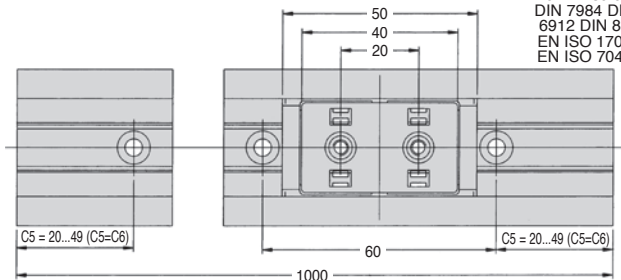


DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-6%	On request

Part number	Type	Weight (g)	Stock*	Price each 1 to 4
NK02-40-1000	1 Rail (1000mm) + 1 slide	480	✓	78,21 €
NW02-40	1 slide only	30	✓	8,93 €

*Depending on availability - Dimensions in mm

 Our other products



Flat profile - Round guide, Flat profile - round guide



Screw-on base for hook-and-loop strip, Polyamide



Stainless steel spur gear, Stainless steel 304L



Articulated foot Ø83, Ø 83



Articulated levelling foot, pressed base Ø100, Ø 100



Stainless steel/Polymer flanged bearing, Polymer and stainless steel



Machined plastic bevel gear, 2:1



Worm and wheel set, Non hardened steel



Reaction arm, CHB gear reducers



Compact precision slide, from 156 N to



Steel bevel gear, 2:1



Bellows cover, Accessory:

Complementary products



Drylin® Rail end cap, Rail end cap