


NK40 NW40


Load up to 700N

- Linear rail with polymer slide
- Reduced size (both height and surface)
- Dry working, no maintenance required
- Not affected by dust
- Corrosion-resistant
- Reduced coefficient of friction means wear is reduced
- Reduced weight thanks to use of a combination of aluminium and plastic
- Very high speeds and acceleration possible
- Replaceable sliding parts in iglidur® J
- Materials:
 - Slide body: Zinc
 - Rails: Anodised aluminium
- Symmetrical hole pattern, C5=C6

Small but effective

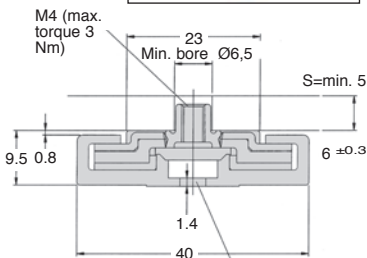

For M4 screw
DIN 7984 DIN
6912 DIN 84
EN ISO 1707
EN ISO 7045

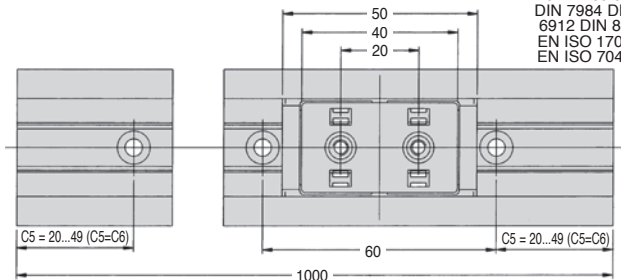

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-6%	On request

Part number	Type	Weight (g)	Stock*	Price each 1 to 4
NK02-40-1000	1 Rail (1000mm) + 1 slide	480	✓	78,21 €
NW02-40	1 slide only	30	✓	8,93 €

*Depending on availability - Dimensions in mm

Our other products



CHM110

Worm and wheel gear reducer, up to 980 Nm



NSA

Adjustable clamp, Articulated



CHA1056_U4

Screw-in hinge, Section 40X40



 
WFRM

Flanged polymer nut, Polymer (Iglidur®) - 1 thread



PW_PWG05

Worm - precision range, Steel



NK80

Drylin@N miniature guiding system, Width 80mm



RHTplss

High Temperature Castor, up to 200kg



SLHVlok

Horizontal toggle clamp, Horizontal toggle clamp / vertical foot



CHAL3

Piano hinge, Aluminium



PML

Solid foot mount for heavy loads, Ø 100, 120 or 150



DOMI30

Accessories, Fixing kit



PX

Optional output shaft stainless steel, P gearboxes single sided outp...

Complementary products



NSKB

Drylin® Rail end cap, Rail end cap