
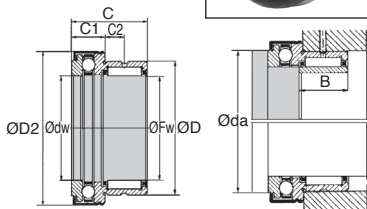


Combined bearing

NKX

With needles and thrust ball bearing
without internal ring

- Combined bearing to support radial and axial loads
- Supplied without internal ring: the shaft will be used as a bearing race, and will therefore have to be hardened and rectified.
- Bearing with protective cap
- Materials:
Steel

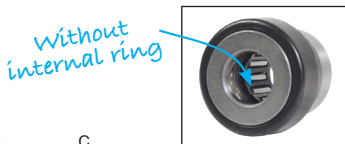

Mounting dimensions

DISCOUNTS

Qty	1+	4+	8+
Disc.	List -15%	On request	

Info.

- In the case of grease lubrication, maximum speed equivalent to 60% of the values in the table.

⁽¹⁾ Axial load F_a from 1 to 2 % of the dynamic load coefficient C (axial)

Part number	Ød	Radial load (N)		Axial load ⁽¹⁾ (N)		Speed (rpm) lubrication oil	Weight (g)
		Dynamic (C)	Static (Co)	Dynamic (C)	Static (Co)		
NKX12Z	12	8500	10500	10000	15000	11000	40
NKX15Z	15	10000	12000	10000	16000	9500	47
NKX17Z	17	11000	14500	10500	17900	8500	55
NKX20Z	20	15000	2500	13500	23000	7500	90
NKX25Z	25	17000	30000	18000	35000	6000	132
NKX30Z	30	21000	34000	19000	39500	5000	148
NKX35Z	35	23000	40000	20500	44650	4600	168
NKX40Z	40	25000	45000	26000	60000	4000	208
NKX45Z	45	26500	51000	27000	67000	3600	265
NKX50Z	50	36000	72000	28000	72000	3300	300

Part number	ØFw	ØD	ØD2 max	C -0,25	C1 -0,2	C2	Ødw	Øda	Stock*	Price each
										1 to 3
NKX12Z	12	21	27,2	23	9	6,5	12	21,7		30,54 □
NKX15Z	15	24	29,2	23	9	6,5	15	23,7		31,29 □
NKX17Z	17	26	31,2	25	9	8,0	17	25,7		33,10 □
NKX20Z	20	30	36,2	30	10	10,5	20	30,7		38,48 □
NKX25Z	25	37	43,2	30	11	9,5	25	37,7		43,72 □
NKX30Z	30	42	48,2	30	11	9,5	30	42,7		55,97 □
NKX35Z	35	47	53,2	30	12	9,0	35	47,7		65,18 □
NKX40Z	40	52	61,2	32	13	10,0	40	55,7		71,17 □
NKX45Z	45	58	66,5	32	14	9,0	45	60,5		82,26 □
NKX50Z	50	62	71,5	35	14	10,0	50	65,5		89,67 □

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



DB
Steel bevel gear, 2:1



Gdal
Double universal joint
eco series, Low duty



DOMI50
Domino 50 adjustable
slide, Slide DOMILINE
50



RFK58C
Hypoid gearbox -
Stainless steel, up to
500 Nm



PPJ
Indexing plunger with
flange, With
horizontal mounting
flange and pu...



PSG15
Spur gear - precision
range, Case hardened
steel 20NCD2



AZY
Cylindrical elasto
mount, Steel



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot



BUH77
Motor-gearbox 12V
and 24V DC, from 0.1



T5-16ECO
T type timing pulley,
Economy range - T5



SLV
Vertical toggle clamp,
Vertical Lever Clamp -



P40
Worm and wheel gear
reducer, up to 18 Nm

Complementary products



NKIA
Combined bearing
with inner ring, Axial
load in one direction



NKXR
Combined bearing
without inner ring,
Needle and cylindrical
rollers



EAR
Bearing locknut, Self
locking locknut - nylon
lock washer



QTR
Tapered roller
bearing, Steel