
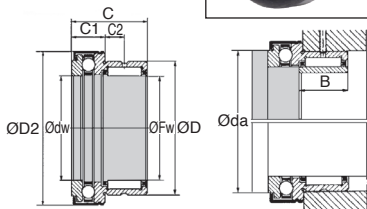


Combined bearing

NKX

With needles and thrust ball bearing
without internal ring

- Combined bearing to support radial and axial loads
- Supplied without internal ring: the shaft will be used as a bearing race, and will therefore have to be hardened and rectified.
- Bearing with protective cap
- Materials:
Steel

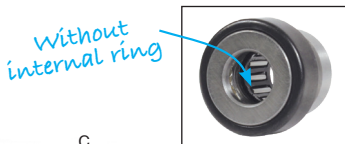

Mounting dimensions

DISCOUNTS

Qty	1+	4+	8+
Disc.	List -15%	On request	

Info.

- In the case of grease lubrication, maximum speed equivalent to 60% of the values in the table.

⁽¹⁾Axial load F_a from 1 to 2 % of the dynamic load coefficient C (axial)

Part number	Ød	Radial load (N)		Axial load ⁽¹⁾ (N)		Speed (rpm) lubrication oil	Weight (g)
		Dynamic (C)	Static (Co)	Dynamic (C)	Static (Co)		
NKX12Z	12	8500	10500	10000	15000	11000	40
NKX15Z	15	10000	12000	10000	16000	9500	47
NKX17Z	17	11000	14500	10500	17900	8500	55
NKX20Z	20	15000	2500	13500	23000	7500	90
NKX25Z	25	17000	30000	18000	35000	6000	132
NKX30Z	30	21000	34000	19000	39500	5000	148
NKX35Z	35	23000	40000	20500	44650	4600	168
NKX40Z	40	25000	45000	26000	60000	4000	208
NKX45Z	45	26500	51000	27000	67000	3600	265
NKX50Z	50	36000	72000	28000	72000	3300	300

Part number	ØFw	ØD	ØD2 max	C -0,25	C1 -0,2	C2	Ødw	Øda	Stock*	Price each
										1 to 3
NKX12Z	12	21	27,2	23	9	6,5	12	21,7		30,54 □
NKX15Z	15	24	29,2	23	9	6,5	15	23,7		31,29 □
NKX17Z	17	26	31,2	25	9	8,0	17	25,7		33,10 □
NKX20Z	20	30	36,2	30	10	10,5	20	30,7		38,48 □
NKX25Z	25	37	43,2	30	11	9,5	25	37,7		43,72 □
NKX30Z	30	42	48,2	30	11	9,5	30	42,7		55,97 □
NKX35Z	35	47	53,2	30	12	9,0	35	47,7		65,18 □
NKX40Z	40	52	61,2	32	13	10,0	40	55,7		71,17 □
NKX45Z	45	58	66,5	32	14	9,0	45	60,5		82,26 □
NKX50Z	50	62	71,5	35	14	10,0	50	65,5		89,67 □

*Depending on availability - Dimensions in mm

Our other products



SHW
Plain washer, A2
Stainless steel



VBFP
Small 6 lobe threaded
handle - female,
Duroplast - Stainless
steel



PSG25
Spur gear - precision
range, Case hardened
steel 20NCD2



SCE_SS
Stainless steel U-
shaped clamp,
Stainless steel



MRS
Stainless steel metric
section rack, Stainless
steel



BPVM
Miniature ball transfer
unit, Miniature to
screw



MPS
Hexagonal spacer,
Stainless steel 303



H1
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



CLR
Straight clevis,
Straight clevis for use



PO
Pull handle - Multi-
sector, Smooth hole



UCP_PBT
Stainless/Polymer
pillow block bearing,



GG3
Ground spur gear,
Heat treated steel

 
Complementary products



NKXR
Combined bearing
without inner ring,
Needle and cylindrical
rollers



QTR
Tapered roller
bearing, Steel



KM
Bearing locknut,
Locknut KM



EAR
Bearing locknut, Self
locking locknut - nylon
lock washer