



Sensor carrier assembly


Supplied ready assembled

PCP

- Assembly comprising one base, two rods, one cross clamp and a cell carrier
- Material: reinforced polyamide
Rods: stainless steel (304) tube
Screws: stainless steel

Info.

- Can be mounted on PRF aluminium profile

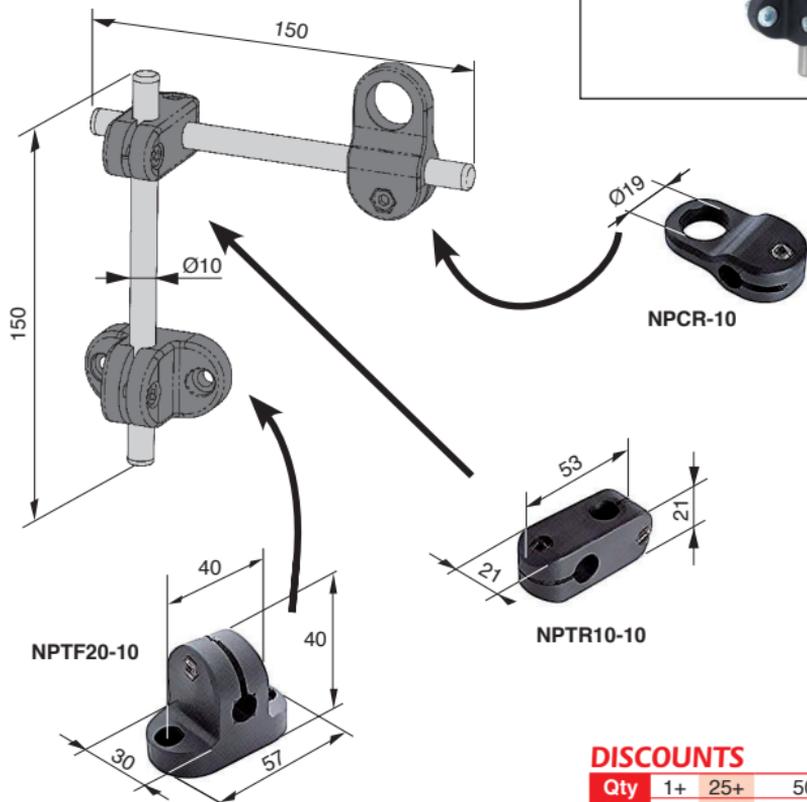

DISCOUNTS

| Qty | 1+ | 25+ | 50+ |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

Part number

PCP10-150

Stock*



Price each
1 to 24

34,00 €

*Depending on availability - Dimensions in mm

Fixed tube carrier



NPTF20

For Ø10 to Ø14 tubes

- For round or square tubes


- Materials:

Body: reinforced polyamide

Screws: stainless steel

Info.

- Not sold individually, please contact us for details

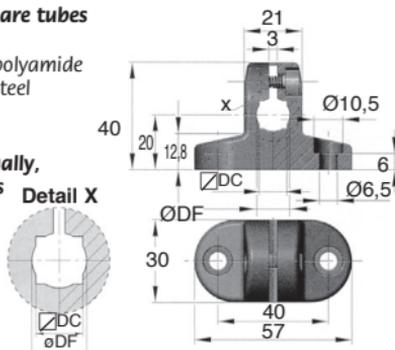

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 30+ | 40+ | 60+ |
| Disc. List | -5% | -10% | On request | |

| Part number | Ø DF | ∅ DC | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|------|------|-------------|--------|--------------------|
| NPTF20-10 | 10 | 8 | 0,03 | ✓ | 6,09 € |
| NPTF20-12 | 12 | 10 | 0,03 | ✓ | 6,71 € |
| NPTF20-14 | 14 | 12 | 0,03 | ✓ | 6,77 € |

*Depending on availability - Dimensions in mm

NPTF20

Spacer for tube carrier


ENT

Plastic


- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

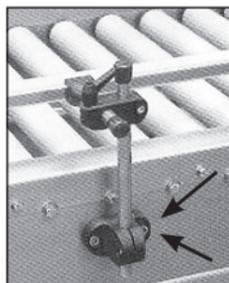

Typical application

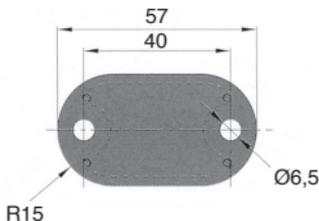

DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 30+ | 40+ | 60+ |
| Disc. List | -5% | -10% | On request | |

| Part number | H | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|---|-------------|--------|--------------------|
| NPTF20-ENT4 | 4 | 0,01 | ✓ | 3,22 € |
| NPTF20-ENT6 | 6 | 0,02 | ✓ | 3,22 € |

*Depending on availability - Dimensions in mm

- For round or square tubes


- Materials:

Body: reinforced polyamide

Screws: stainless steel

Accessories

- APB-F and APB-T adjusting rods (tome 5 p.118, p.119)

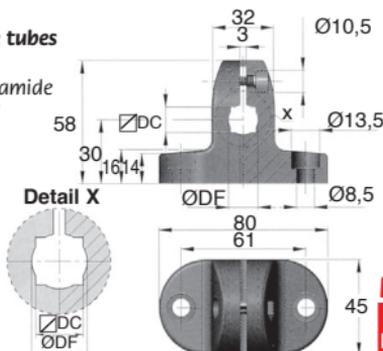

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|------------|-----|------|------------|------------|
| Disc. List | -5% | -10% | On request | On request |

| Part number | ØDF | ØDC | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|-----|-----|-------------|--------|--------------------|
| NPTF30-14 | 14 | 12 | 0,09 | ✓ | 13,39 € |
| NPTF30-16 | 16 | 14 | 0,09 | ✓ | 13,39 € |
| NPTF30-18 | 18 | 16 | 0,09 | ✓ | 13,39 € |
| NPTF30-20 | 20 | 18 | 0,09 | ✓ | 13,39 € |

*Depending on availability - Dimensions in mm

Spacer for tube carrier

Plastic


NPTF30

ENT


- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

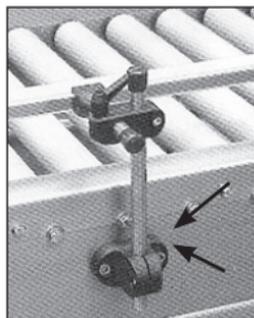

Typical application

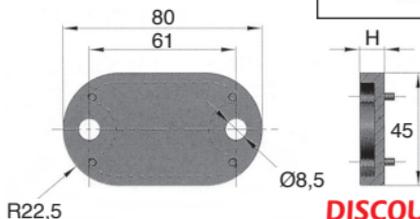

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|------------|-----|------|------------|------------|
| Disc. List | -5% | -10% | On request | On request |

| Part number | H | Weight (kg) | Stock* | Price each 1 to 29 |
|--------------|----|-------------|--------|--------------------|
| NPTF30-ENT10 | 10 | 0,03 | - | 3,41 € |

*Depending on availability - Dimensions in mm

Adjustable cross clamp

Pla  Stock

NPTR_M


Quick adjustment

- For $\varnothing 14$ to $\varnothing 20$ round tube
- Materials:
Body: reinforced polyamide
Screws: stainless steel
Thread inserts: zinc plated steel


Accessories

- APB-F and APB-T adjusting rods
(tome 5 p.118, p.119)

Quick
adjustment

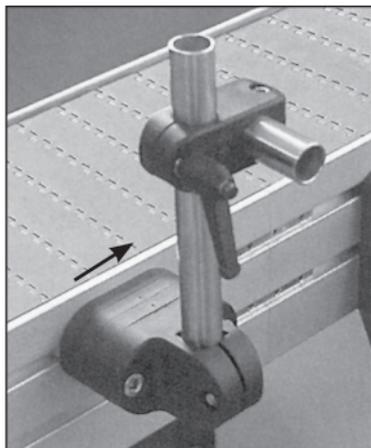

Typical application

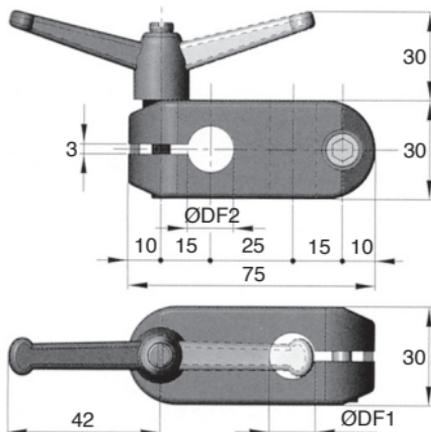

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | ØDF1 | ØDF2 | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|------|------|-------------|--------|--------------------|
| NPTR14-14/M | 14 | 14 | 0,09 | ✓ | 18,50 € |
| NPTR15-15/M | 15 | 15 | 0,09 | - | 18,50 € |
| NPTR16-16/M | 16 | 16 | 0,09 | ✓ | 18,50 € |
| NPTR18-18/M | 18 | 18 | 0,09 | - | 18,50 € |
| NPTR20-20/M | 20 | 20 | 0,09 | ✓ | 18,50 € |

*Depending on availability - Dimensions in mm





- For $\varnothing 14$ to $\varnothing 20$ round tube
- Materials:
Body: reinforced polyamide
Screws: stainless steel

Info.

- Not sold individually, please contact us for details

Accessories

- APB-F and APB-T adjusting rods
(tome 5 p.118, p.119)

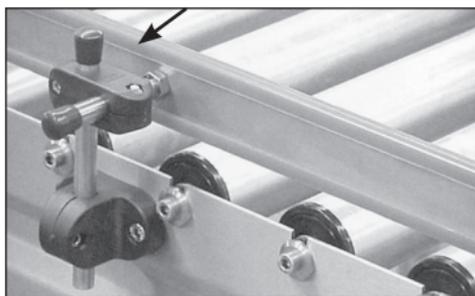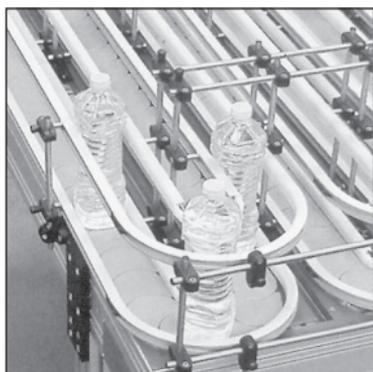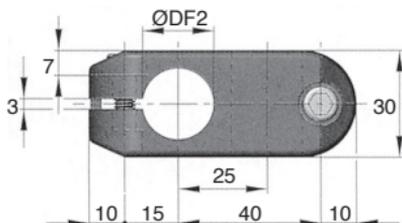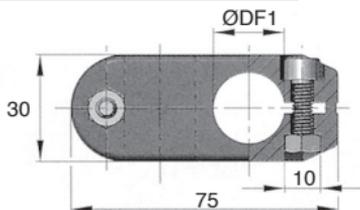

↑
← Typical applications

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | ØDF1 | ØDF2 | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|------|------|-------------|--------|--------------------|
| NPTR14-14 | 14 | 14 | 0,07 | ✓ | 6,97 € |
| NPTR14-15 | 14 | 15 | 0,07 | - | 6,97 € |
| NPTR14-16 | 14 | 16 | 0,07 | - | 6,97 € |
| NPTR15-15 | 15 | 15 | 0,07 | - | 6,97 € |
| NPTR15-16 | 15 | 16 | 0,07 | - | 6,97 € |
| NPTR16-16 | 16 | 16 | 0,07 | ✓ | 6,97 € |
| NPTR18-18 | 18 | 18 | 0,07 | ✓ | 6,97 € |
| NPTR20-20 | 20 | 20 | 0,07 | ✓ | 6,97 € |

*Depending on availability - Dimensions in mm

Adjustable cross clamp



NPTR

Standard version for 10mm and 12mm rods

- For $\varnothing 10$ and $\varnothing 12$ round tubes or 8mm and 10mm square rods

- Materials:


Reinforced polyamide / Screws: stainless steel

Info.

- Not sold individually,
please contact us for details

Accessories

- APB-F and APB-T adjusting rods
(tome 5 p.118, p.119)

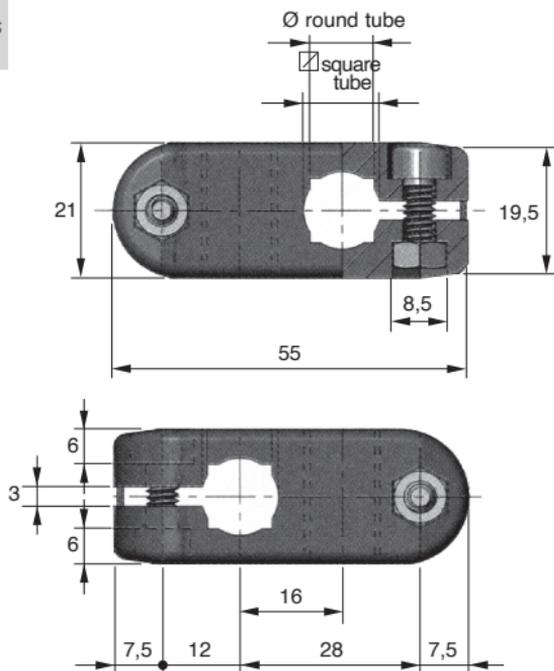

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|------------|-----|------|-----|------------|
| Disc. List | -5% | -10% | | On request |

| Part number | \varnothing round tube | \square square tube | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|--------------------------|-----------------------|-------------|--------|--------------------|
| NPTR10-10 | 10 | 8 | 0,03 | ✓ | 6,33 € |
| NPTR12-12 | 12 | 10 | 0,03 | ✓ | 6,33 € |

*Depending on availability - Dimensions in mm


- For round or square tube
- Materials:
Body: reinforced polyamide
Screws: stainless steel

Info.

- Not sold individually, please contact us for details

Accessories

- APB-F and APB-T adjusting rods (tome 5 p.118, p.119)

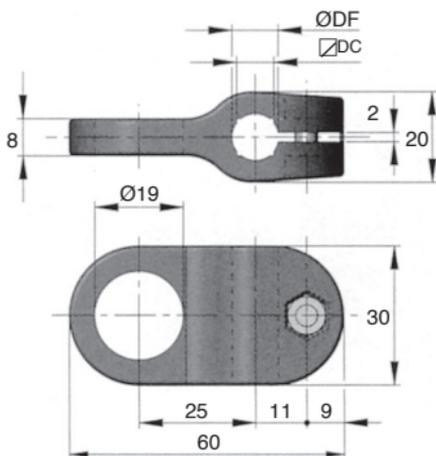

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 30+ | 40+ | 60+ |
| Disc. | List | -5% | -10% | On request |

| Part number | ØDF | Ø DC | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|-----|------|-------------|--------|--------------------|
| NPCR-10 | 10 | 8 | 0,02 | ✓ | 6,21 € |
| NPCR-12 | 12 | 10 | 0,02 | ✓ | 6,09 € |
| NPCR-14 | 14 | 12 | 0,02 | ✓ | 6,63 € |

*Depending on availability - Dimensions in mm

Reflector support




NPR

Plastic

- For round tube
- Materials:
 - Body: reinforced polyamide
 - Screws: stainless steel

Accessories

- APB-F and APB-T adjusting rods (tome 5 p.118, p.119)

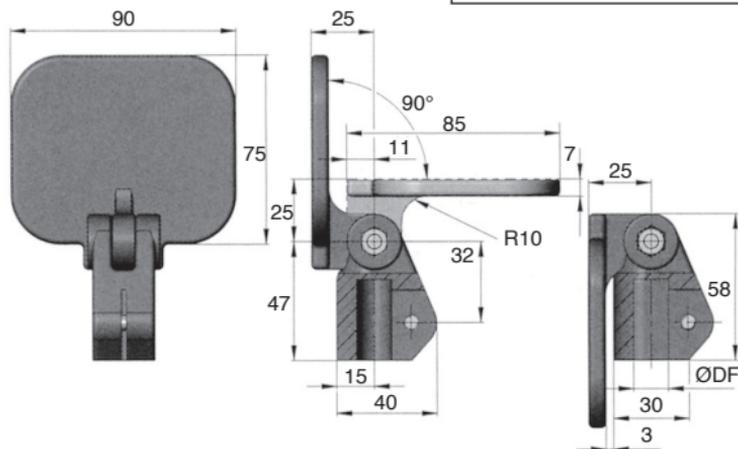

DISCOUNTS

| Qty | 1+ | 30+ | 40+ | 60+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | ØDF | Weight (kg) | Stock* | Price each 1 to 29 |
|-------------|-----|-------------|--------|--------------------|
| NPR-12 | 12 | 0,1 | ✓ | 24,87 € |
| NPR-14 | 14 | 0,1 | ✓ | 24,87 € |
| NPR-15 | 15 | 0,1 | - | 24,87 € |
| NPR-16 | 16 | 0,1 | - | 24,87 € |
| NPR-18 | 18 | 0,1 | - | 24,87 € |
| NPR-20 | 20 | 0,1 | - | 24,87 € |

*Depending on availability - Dimensions in mm



Articulated clamp


For rod or tube

NSA

- For clamping cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob for quick tightening

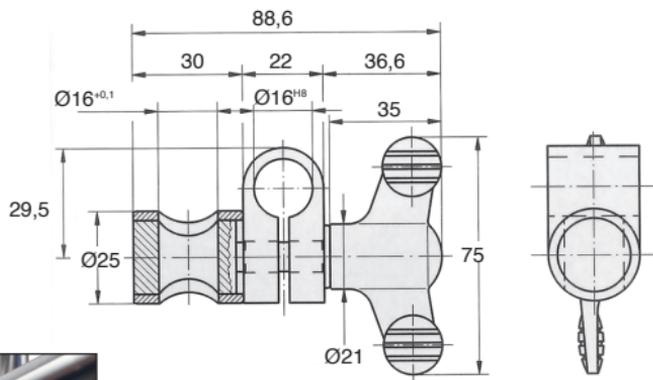

Typical application

DISCOUNTS

| Qty | 1+ | 5+ | 10+ |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | For rod | Weight (kg) | Stock* | Price each 1 to 4 |
|-------------|---------|-------------|--------|-------------------|
| NSA-16 | Ø16 | 0,150 | ✓ | 69,28 € |

*Depending on availability - Dimensions in mm

Adjustable clamp



NSR

For rod or tube

- Holds cylindrical sections (rods, tubes...)


- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: steel, resistance class 5.8


Other parts: high-resistance anodised aluminium

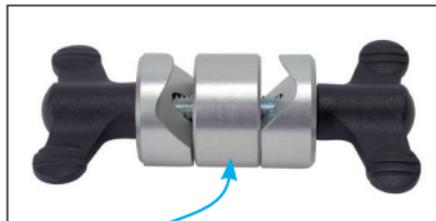

Aluminium

Advantages

- Each side adjusts individually, no bearing
- Simple construction using wing nuts
- Tightens quickly

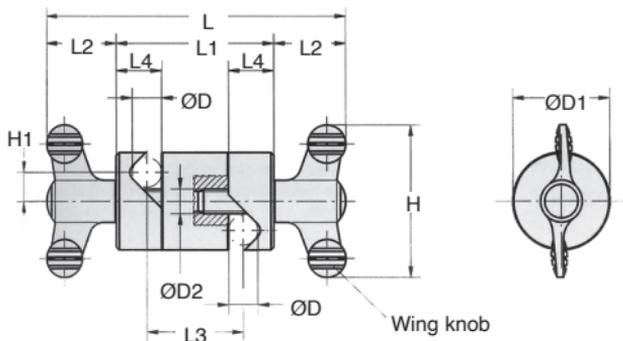

Typical application

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 5+ | 10+ |
| Disc. | List | -10% | On request |

| Part number | ØD | ØD1 | ØD2 | L | L1 | L2 | L3 | L4 | H | H1 | Weight (kg) | Stock* | Price each 1 to 4 |
|-------------|----|-----|-----|-----|-----|----|----|----|----|------|-------------|--------|-------------------|
| NSR-8 | 8 | 28 | M8 | 90 | 42 | 24 | 24 | 13 | 50 | 8,5 | 0,086 | - | 50,20 € |
| NSR-10 | 10 | 32 | M8 | 100 | 52 | 24 | 32 | 15 | 50 | 9,5 | 0,124 | ✓ | 52,54 € |
| NSR-12 | 12 | 36 | M8 | 104 | 56 | 24 | 34 | 17 | 50 | 10,5 | 0,157 | ✓ | 60,16 € |
| NSR-16 | 16 | 45 | M10 | 142 | 72 | 35 | 44 | 22 | 75 | 13,5 | 0,345 | ✓ | 76,66 € |
| NSR-20 | 20 | 74 | M10 | 172 | 102 | 35 | 62 | 30 | 75 | 22,0 | 1,110 | ✓ | 116,47 € |

*Depending on availability - Dimensions in mm



Multiple junction clamp


For rod or tube

NJM


- For extending cylindrical sections, either in-line or parallel mounting
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Screw: resistance class 5.8, yellow chromate plated steel
Body: high-resistance anodised aluminium

Advantages

- Parallel mounting arrangement can be used to strengthen a structure
- Additional holes in body allow orthogonal joints to be assembled

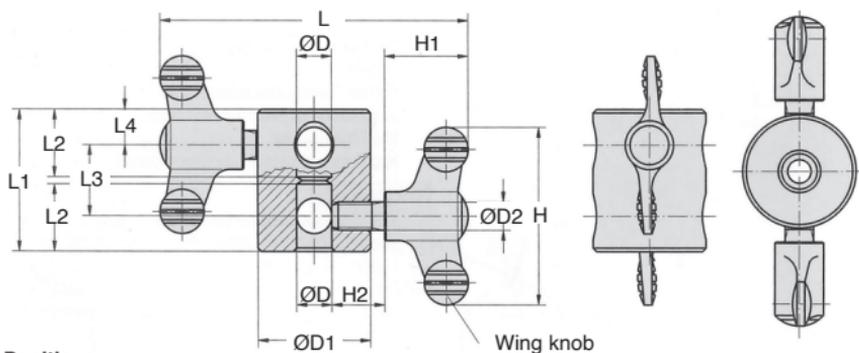

Positions:

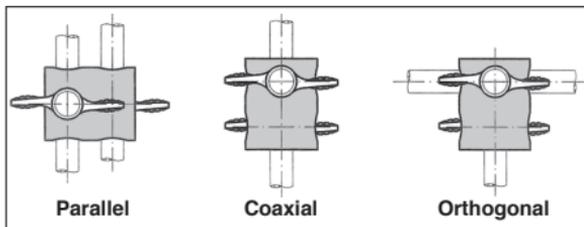

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 5+ | 10+ |
| Disc. | List | -10% | On request |

| Part number | ØD | ØD1 | ØD2 | L | L1 | L2 | L3 | L4 | H | H1 | H2 | Weight (kg) | Stock* | Price each 1 to 4 |
|-------------|----|-----|-----|-----|----|----|----|----|----|----|----|-------------|--------|-------------------|
| NJM-8 | 8 | 28 | M8 | 89 | 36 | 17 | 20 | 8 | 50 | 24 | 15 | 0,074 | - | 50,19 € |
| NJM-10 | 10 | 32 | M8 | 90 | 40 | 19 | 20 | 10 | 50 | 24 | 15 | 0,093 | - | 52,54 € |
| NJM-12 | 12 | 36 | M8 | 90 | 44 | 21 | 20 | 12 | 50 | 24 | 15 | 0,118 | - | 60,09 € |
| NJM-16 | 16 | 45 | M10 | 126 | 56 | 27 | 24 | 16 | 75 | 35 | 20 | 0,262 | - | 76,66 € |

*Depending on availability - Dimensions in mm